

Universal Busbar Support with Neutral Circuit, High Ampacity



CERTIFICERINGER



FUNKTIONER

Universal fixing system

Installs quickly and easily

Extremely robust construction

Screws are made from non-magnetic stainless steel

Halogen free insulators

SPECIFIKATIONER

Max Working Voltage, IEC (Ui):	1000;1500
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C


Table 1/2

Katalognummer	Artikelnummer	Materiale	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness
UBS2-10TN-160	561870	Stål, Glass Fibre Reinforced Polyamide	5700 A	1 - 2	160 mm	10 mm
UBS2-10TN-200	561880	Stål, Glass Fibre Reinforced Polyamide	5700 A	1 - 2	200 mm	10 mm
UBS3-10TN-160	561540	Stål, Glass Fibre Reinforced Polyamide	6200 A	1 - 3	160 mm	10 mm
UBS1-10TN-160	561500	Stål, Glass Fibre Reinforced Polyamide	3500 A	1	160 mm	10 mm

Table 2/2

Katalognummer	Artikelnummer	Width (W)	A
UBS2-10TN-160	561870	480 mm	110 mm
UBS2-10TN-200	561880	480 mm	110 mm
UBS3-10TN-160	561540	480 mm	110 mm
UBS1-10TN-160	561500	300 mm	70 mm

DIAGRAMS

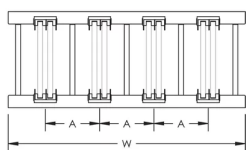

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE