

B-Series Horizontal Sleeve, Top Fill



The top fill horizontal B-Series sleeve is designed to be welded perpendicularly to common grades of structural plates and shapes. Typical applications include welding to base plates, anchor plates and for tying together structural steel members.

Vent holes are added to horizontal sleeves to reduce air entrapment and help ensure proper filling of the sleeve.

FUNKTIONER

Designed to connect horizontal reinforcing bars and angular reinforcing bars up to 45 degrees

Machined from weldable grades of steel

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

SPECIFIKATIONER

Table 1/3

Katalognummer	Materiale	Finish	100% U.S. Domestic Content	Sleeve	Rebar Size, Metric	Rebar Size, US
RBB14101JAPB	Stål	Plain	Yes	Standard Length	43 mm	#14

Table 2/3

Katalognummer	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Length 1 (L1)	Length 2 (L2)	Length 3 (L3)
RBB14101JAPB	45M	76 mm	54 mm	152 mm	64 mm	26mm

Table 3/3

Katalognummer	Unit Weight
---------------	-------------

RBB14101JAPB

2.72 kg

**Designed to
Meet:**


AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

YDERLIGERE PRODUKTOPLYSNINGER

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

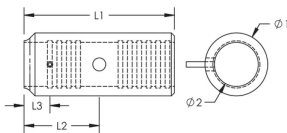

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY**ERICO****HOFFMAN****ILSCO****SCHROFF****TRACHTE**