

# ELICP Internal Plastic nVent LENTON Form Saver Plug for A2 Couplers



## FUNKTIONER

Designed for use with the A2 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

O-ring provides hydraulic seal

Color coded for the appropriate coupler size

## SPEKIFIKATIONER

**Materiale:** High Density Polyethylene (HDPE)

Table 1/2

| Katalognummer | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Width 1 (W1) | Width 2 (W2) | A     |
|---------------|--------------------|----------------|--------------------|--------------|--------------|-------|
| ELICP20       | 20 mm              | #6             | 20M                | 57 mm        | 13 mm        | 10 mm |
| ELICP22       | 22 mm              | #7             |                    | 60 mm        | 13 mm        | 13 mm |
| ELICP25       | 25 mm              | #8             | 25M                | 64 mm        | 13 mm        | 13 mm |
| ELICP28       | 28 mm              | #9             | 30M                | 67 mm        | 13 mm        | 13 mm |

| Katalognummer | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Width 1 (W1) | Width 2 (W2) | A     |
|---------------|--------------------|----------------|--------------------|--------------|--------------|-------|
| ELICP32       | 32 mm              | #10            |                    | 70 mm        | 13 mm        | 13 mm |
| ELICP36       | 36 mm              | #11            | 35M                | 75 mm        | 13 mm        | 13 mm |
| ELICP43       | 43 mm              | #14            | 45M                | 83 mm        | 16 mm        | 13 mm |
| ELICP57       | 57 mm              | #18            | 55M                | 102 mm       | 25 mm        | 13 mm |


Table 2/2

| Katalognummer | Height (H) | Farve  |
|---------------|------------|--------|
| ELICP20       | 11 mm      | Yellow |
| ELICP22       | 11 mm      | Blue   |
| ELICP25       | 11 mm      | Red    |
| ELICP28       | 11 mm      | Black  |
| ELICP32       | 11 mm      | Yellow |
| ELICP36       | 11 mm      | Blue   |
| ELICP43       | 11 mm      | Red    |
| ELICP57       | 11 mm      | Blue   |

## YDERLIGERE PRODUKTOPLYSNINGER

ELICP36 can also be used with P8/P9 position couplers for form saving applications (sizes 20, 22, 25 only).

## DIAGRAMS

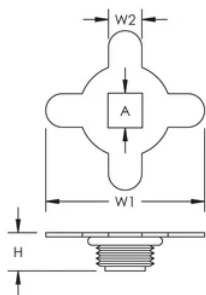

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**