

# Horizontal Pouring Basin, Side Fill, Extended



Extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

## FUNKTIONER

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

## SPECIFIKATIONER

**Materiale:** Graphite

Table 1/1

| Katalognummer | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) | Width (W) | Height 1 (H1) | Height 2 (H2) |
|---------------|--------------|---------------|---------------|-----------|---------------|---------------|
| RBHSA9750X    | 38 mm        | 248 mm        | 38 mm         | 76 mm     | 127mm         | 76mm          |
| RBHSB10560X   | 38 mm        | 267 mm        | 38 mm         | 76 mm     | 152mm         | 76mm          |
| RBHSB12065X   | 38 mm        | 305 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSA9050D    | 54 mm        | 229 mm        | 38 mm         | 76 mm     | 127mm         | 76mm          |
| RBHSA9050F    | 64 mm        | 229 mm        | 38 mm         | 76 mm     | 127mm         | 76mm          |
| RBHSA9560M    | 95 mm        | 241 mm        | 38 mm         | 76 mm     | 152mm         | 76mm          |

| Katalognummer | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) | Width (W) | Height 1 (H1) | Height 2 (H2) |
|---------------|--------------|---------------|---------------|-----------|---------------|---------------|
| RBHSB12065C   | 48 mm        | 305 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSB12065F   | 64 mm        | 305 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSB12065J   | 76 mm        | 305 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSB12065M   | 95 mm        | 305 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSB14065F   | 64 mm        | 356 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSB14065J   | 76 mm        | 356 mm        | 38 mm         | 76 mm     | 165mm         | 76mm          |
| RBHSB14070D   | 54 mm        | 356 mm        | 38 mm         | 76 mm     | 178mm         | 76mm          |
| RBHSB14075M   | 95 mm        | 356 mm        | 38 mm         | 76 mm     | 191mm         | 76mm          |
| RBHSB16070F   | 64 mm        | 406 mm        | 38 mm         | 76 mm     | 178mm         | 76mm          |
| RBHSB17070C   | 48 mm        | 432 mm        | 38 mm         | 76 mm     | 178mm         | 76mm          |
| RBHSB177550M  | 95 mm        | 451 mm        | 38 mm         | 76 mm     | 127mm         | 76mm          |
| RBHSC23010M   | 95 mm        | 584 mm        | 38 mm         | 76 mm     | 254mm         | 76mm          |
| RBHSC23075M   | 95 mm        | 584 mm        | 38 mm         | 76 mm     | 191mm         | 76mm          |
| RBHSC30070D   | 54 mm        | 762 mm        | 38 mm         | 76 mm     | 191mm         | 76mm          |


## YDERLIGERE PRODUKTOPLYSNINGER

RBHSA pouring basins require one RBW332 pouring basin frame and two RBS5000 bolt retainers. RBHSB pouring basins require one RBW3321 pouring basin frame and one RBS5000 bolt retainer. RBHSC pouring basins require one RBW3322 pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

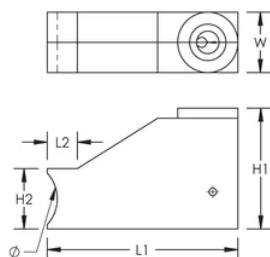

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**