

Horizontal Pouring Basin, Top Fill, 90°



90 degree top fill horizontal pouring basins are used when structural interferences are directly above the tap hole in the sleeve.

FUNKTIONER

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

SPECIFIKATIONER

Materiale: Graphite

Table 1/1

Katalognummer	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)	Width (W)	Height 1 (H1)	Height 2 (H2)
RB TSA9040X	38 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSA9735X	38 mm	248 mm	76 mm	76 mm	140mm	89mm
RB TSA6040F	64 mm	152 mm	76 mm	76 mm	140mm	102mm
RB TSA9740A	41 mm	248 mm	76 mm	76 mm	140mm	102mm
RB TSA7040J	76 mm	179 mm	76 mm	76 mm	140mm	102mm
RB TSA9040C	48 mm	229 mm	76 mm	76 mm	140mm	102mm

Katalognummer	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)	Width (W)	Height 1 (H1)	Height 2 (H2)
RB TSA9740C	48 mm	248 mm	76 mm	76 mm	140mm	102mm
RB TSA9040D	54 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB15045D	54 mm	381 mm	76 mm	76 mm	152mm	114mm
RB TSB12040E	57 mm	305 mm	76 mm	76 mm	152mm	102mm
RB TSA9040F	64 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB12042F	64 mm	305 mm	76 mm	76 mm	152mm	108mm
RB TSA9040J	76 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB13545J	76 mm	342 mm	76 mm	76 mm	152mm	114mm
RB TSA9040M	95 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB12050M	95 mm	305 mm	76 mm	76 mm	152mm	127mm
RB TSB15045M	95 mm	381 mm	76 mm	76 mm	152mm	114mm
RB TSB18550M	95 mm	470 mm	76 mm	76 mm	152mm	127mm
RB TSC18550M	95 mm	470 mm	76 mm	76 mm	179mm	127mm
RB TSC26050M	95 mm	660 mm	76 mm	76 mm	179mm	127mm


YDERLIGERE PRODUKTOPLYSNINGER

RB TSA pouring basins require one RBW341 pouring basin frame. RB TSB and RB TSC pouring basins require one RBW341 pouring basin frame and two RBS5000 bolt retainers (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

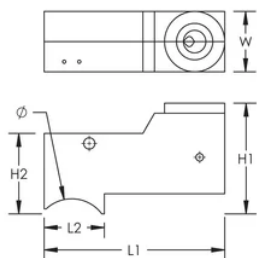

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE