

nVent LENTON Interlok Grommet



The nVent LENTON Grommet is used in conjunction with the nVent LENTON Bolted Form Mount and nVent LENTON Toggle Form Mount. These Grommets are used to secure nVent LENTON Interlok Grout-Fill Coupler variants in repeatable locations in the formwork. Once a Grout-Fill Coupler is placed over a Grommet, the Form Mount bolt is tightened, which expands the outside diameter of the Grommet, thus holding the Grout-Fill Coupler in place.

FUNKTIONER

Color-coded for the appropriate coupler size

Durable and reusable

SPECIFIKATIONER

Materiale: Polyester Urethane

Table 1/2

Katalognummer	Artikelnummer	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Length (L)	For Use With	Farve
LK307A	145811	46 mm	19 mm	52mm	LK5, LK6, LK7	Blue
LK308A	145812	49 mm	19 mm	52mm	LK8	Red
LK316A		40 mm	19 mm	51mm	LK16	Black
LK320A		43 mm	19 mm	51mm	LK20	Yellow
LK309A	145813	52 mm	19 mm	52mm	LK9	Black
LK310A	145814	57 mm	19 mm	52mm	LK10	Yellow

Katalognummer	Artikelnummer	Diameter 1(Ø1)	Diameter 2(Ø2)	Length (L)	For Use With	Farve
LK311A	145815	60 mm	19 mm	52mm	LK11	Blue
LK314A	145816	67 mm	19 mm	52mm	LK12, LK40, LKT14	Red
LK318A	145817	83 mm	19 mm	52mm	LKT18, LKT50	Black


Table 2/2

Katalognummer	Artikelnummer	Unit Weight
LK307A	145811	0.08 kg
LK308A	145812	0.09 kg
LK316A		0.12 kg
LK320A		0.15 kg
LK309A	145813	0.11 kg
LK310A	145814	0.13 kg
LK311A	145815	0.15 kg
LK314A	145816	0.22 kg
LK318A	145817	0.5 kg

YDERLIGERE PRODUKTOPLYSNINGER

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

DIAGRAMS

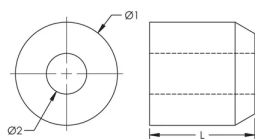

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE