

nVent LENTON Interlok Position Transition Grout-Fill Coupler



FUNKTIONER

Designed to splice different diameter bars

Positional feature allows the threaded coupler end to telescope out to close a gap between forms and to allow alignment of the grout tubes

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

SPECIFIKATIONER

Table 1/3

Katalognummer	Materiale	Finish	Packaging	Rebar Size, Metric	Rebar Size, US	Diameter 1 (Ø1)
LK1110STHD	Cast Iron	Plain	Standard	36 mm, 32 mm	#11, #10	80 mm

Table 2/3

Katalognummer	Diameter 2 (Ø2)	Length 1 (L1)	Length 2 (L2)	Length 3 (L3)	Bar Depth (BD)	Coupler Body (CB)
LK1110STHD	62 mm	384 mm	410 mm	251mm	40mm	305mm

Table 3/3

Katalognummer	Unit Weight
---------------	-------------

LK1110STHD

4.59 kg

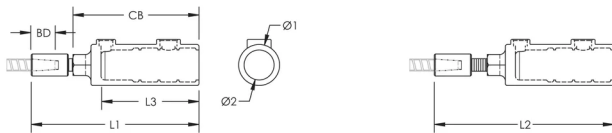
Designed to Meet:

AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

YDERLIGERE PRODUKTOPLYSNINGER

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

DIAGRAMS**ADVARSEL**

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY**ERICO****HOFFMAN****ILSCO****SCHROFF****TRACHTE**