

nVent LENTON Quick Wedge Mechanical Lap Coupler, Plain, Pin Included



The nVent LENTON Quick Wedge splice consists of an oval-shaped steel sleeve and a wedge pin. The sleeve is positioned around two very short overlapping steel bars. The wedge pin is inserted into a handheld hydraulic pin-driver and positioned on the sleeve. The pin is then driven through the pre-drilled hole in the sleeve and between the bars to complete the connection.

FUNKTIONER

Short reinforcing bar overlap significantly reduces concrete removal in retrofit applications

Eliminates the need to custom cut and fit rebar to precise measurements

Quick installations result in accelerated job scheduling

Simple to use with only minimal training required

Splice offers quick visual inspection

Each package contains couplers, wedge pins and a spare grommet

SPECIFIKATIONER

Finish: Plain

Packaging: Standard

Materiale: Stål

Table 1/2

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Length (L)	Width (W)
ML12MM	145700	12 mm			48mm	40 mm
ML5	145710	16 mm	#5	15M	57mm	49 mm
ML20MM	145720	20 mm			70mm	59 mm

Table 2/2


Katalognummer	Artikelnummer	Height (H)	Unit Weight
ML12MM	145700	27 mm	0.23 kg
ML5	145710	33 mm	0.36 kg
ML20MM	145720	40 mm	0.54 kg

Designed to Meet: AASHTO;ACI 318 Type 1 (125% Specified Yield)

YDERLIGERE PRODUKTOPLYSNINGER

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Quick Wedge Operator's Manual.

DIAGRAMS

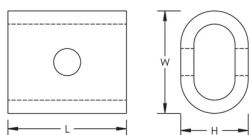

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE