 


PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, Worldwide Design



FUNKTIONER

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFIKATIONER

Design Version: Worldwide (Globally Available Materials)

Table 1/2


Katalognummer	Materiale	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL12PFFN	High Density Polyethylene (HDPE), Stål	12 mm	#4	10M	65 mm	17 mm
EL28PFFN	High Density Polyethylene (HDPE), Stål	28 mm	#9	30M	95 mm	20 mm
EL40PFFN	High Density Polyethylene (HDPE), Stål	40 mm			95 mm	20 mm

Katalognummer	Materiale	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL20PFFN	High Density Polyethylene (HDPE), Stål	20 mm	#6	20M	75 mm	20 mm
EL36PFFN	High Density Polyethylene (HDPE), Stål	36 mm	#11	35M	95 mm	20 mm
EL22PFFN	High Density Polyethylene (HDPE), Stål	22 mm	#7		95 mm	20 mm
EL16PFFN	High Density Polyethylene (HDPE), Stål	16 mm	#5	15M	65 mm	20 mm
EL32PFFN	High Density Polyethylene (HDPE), Stål	32 mm	#10		95 mm	20 mm
EL25PFFN	High Density Polyethylene (HDPE), Stål	25 mm	#8	25M	95 mm	20 mm

Table 2/2

Katalognummer	Farve
EL12PFFN	Red
EL28PFFN	Black
EL40PFFN	Green
EL20PFFN	Yellow
EL36PFFN	Blue
EL22PFFN	Blue
EL16PFFN	Black
EL32PFFN	Yellow
EL25PFFN	Red

DIAGRAMS

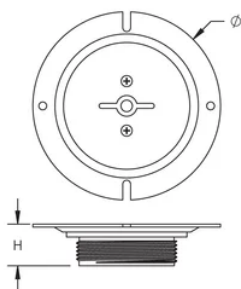

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE