

PPP Parallel Plastic Screw-In Plug for P13/P14, European Design



The European Design Version (Suffix EE) is currently being phased out. All future projects should be designed with the Worldwide Design Version (Suffixes N and LN). This change is being done in order to simplify our product offering and eliminate redundant designs. Please contact Customer Care or your local Sales Engineer/Manager if you require more information on this transition.

FUNKTIONER

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

SPECIFIKATIONER

Design Version: European (Specialty Materials)


Table 1/2

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL1416PPP	153280	14 mm, 16 mm	#5	15M	27 mm	13 mm
EL1012PPP	153240	10 mm, 12 mm	#3, #4	10M	22 mm	13 mm
EL2225PPP	153360	22 mm, 25 mm	#7, #8	25M	41 mm	16 mm
EL18PPP	153310	18 mm			33 mm	16 mm
EL20PPP	153320	20 mm	#6	20M	33 mm	16 mm

Katalognummer	Artikelnummer	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL40PPP	153420	40 mm			64 mm	16 mm
EL2830PPP	153380	28 mm, 30 mm	#9	30M	46 mm	16 mm
EL32PPP	153400	32 mm	#10		52 mm	16 mm

Table 2/2		
Katalognummer	Artikelnummer	Farve
EL1416PPP	153280	Black
EL1012PPP	153240	Red
EL2225PPP	153360	Red
EL18PPP	153310	White
EL20PPP	153320	Yellow
EL40PPP	153420	Green
EL2830PPP	153380	Black
EL32PPP	153400	Yellow

DIAGRAMS

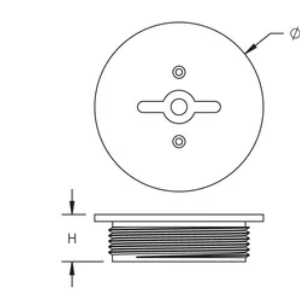

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE