

# T-Series Horizontal Fixed Angle Splice Kit, Top Fill, 15-30°



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

## FUNKTIONER

Simplifies ordering

Used to splice the same diameter bars

## SPECIFIKATIONER

**Sleeve:** Standard Length

Table 1/2

| Katalognummer | Angle (a) | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Length 1 (L1) | Length 2 (L2) |
|---------------|-----------|--------------------|----------------|--------------------|---------------|---------------|
| RBT1110130H   | 30 °      | 36 mm              | #11            | 35M                | 172 mm        | 285 mm        |
| RBT1110115H   | 15 °      | 36 mm              | #11            | 35M                | 167 mm        | 301 mm        |
| RBT109130H    | 30 °      | 32 mm              | #10            |                    | 165 mm        | 285 mm        |
| RBT189115H    | 15 °      | 57 mm              | #18            | 55M                | 208 mm        | 301 mm        |
| RBT189130H    | 30 °      | 57 mm              | #18            | 55M                | 213 mm        | 285 mm        |

Table 2/2

| Katalognummer | Height 1 (H1) | Height 2 (H2) | Diameter (Ø) |
|---------------|---------------|---------------|--------------|
| RBT1110130H   | 496mm         | 200mm         | 127 mm       |
| RBT1110115H   | 506mm         | 138mm         | 127 mm       |
| RBT109130H    | 496mm         | 175mm         | 127 mm       |
| RBT189115H    | 538mm         | 150mm         | 178 mm       |
| RBT189130H    | 528mm         | 207mm         | 178 mm       |

## YDERLIGERE PRODUKTOPLYSNINGER


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

| Splice Kit Components |                 |                        |                                       |                                  |            |               |                        |
|-----------------------|-----------------|------------------------|---------------------------------------|----------------------------------|------------|---------------|------------------------|
| Splice Kit            | Filler Material | Packing (2 Required)   | Pouring Basin Ceramic Insert and Disk | Pouring Basin Ceramic Guide Tube | Sleeve     | Pouring Basin | Pouring Basin Crucible |
| RBT109130H            | RBF90           | RBS354712              | RBS5037                               | RBS5038                          | RBT1091HA  | RBWS2223E     | RBWS22775              |
| RBT1110115H           | RBF105          | RBS354712              | RBS5037                               | RBS5038                          | RBT11101HA | RBWS2222F     | RBWS22775              |
| RBT1110130H           | RBF105          | RBS354712              | RBS5037                               | RBS5038                          | RBT11101HA | RBWS2223F     | RBWS22775              |
| RBT189115H            | RBF270          | RBS354720              | RBS5037                               | RBS5039                          | RBT1891HA  | RBWS2222M     | RBWS22777              |
| RBT189130H            | RBF270          | RBS354720<br>RBS354720 | RBS5037                               | RBS5039                          | RBT1891HA  | RBWS2223M     | RBWS22777              |

## DIAGRAMS

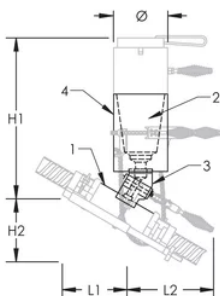

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**