

# T-Series Horizontal Transition Installation Equipment



T-Series horizontal installation equipment kits contain the following: Pouring basin frame, crucible frame set (crucible chain assembly, crucible extension, crucible cover), two end alignment fittings and a horizontal packing clamp. Installation equipment kits contain components that are long lasting and often interchangeable with other sizes. Ordering installation equipment kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

## FUNKTIONER

Simplifies ordering

Used to splice different diameter bars

All components are designed for an extended life

## SPECIFIKATIONER

Table 1/1


| Katalognummer | Materiale      | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada |
|---------------|----------------|--------------------|----------------|--------------------|
| RBW739810H    | Stål, Graphite | 32 mm, 25 mm       | #10, #8        |                    |
| RBW7391411H   | Stål, Graphite | 43 mm, 36 mm       | #14, #11       | 45M, 35M           |
| RBW7391811H   | Stål, Graphite | 57 mm, 36 mm       | #18, #11       | 55M, 35M           |

## YDERLIGERE PRODUKTOPLYSNINGER

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Components can also be purchased separately: (1) Pouring Basin Frame, (2) Crucible Chain Assembly, (3) Crucible Extension, (4) Crucible Cover, (5) End Alignment Fitting, and (6) Horizontal Packing Clamp.

## DIAGRAMS

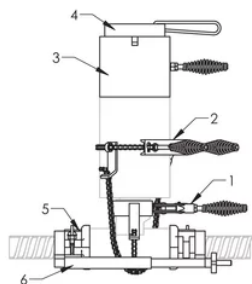

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**