

# Vertical Pouring Basin, Standard



Standard vertical pouring basins should be used whenever the clearances of the structure allow. The compact size of the standard pouring basins help ensure the best possible flow of filler material.

## FUNKTIONER

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series vertical sleeves

## SPECIFIKATIONER

**Materiale:** Graphite

Table 1/1

| Katalognummer | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) | Width (W) | Height 1 (H1) | Height 2 (H2) |
|---------------|--------------|---------------|---------------|-----------|---------------|---------------|
| RBWS1500U     | 35 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |
| RBWS1500X     | 38 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |
| RBWS1481F     | 64 mm        | 152 mm        | 38 mm         | 76 mm     | 159mm         | 95mm          |
| RBWS1481G     | 70 mm        | 152 mm        | 38 mm         | 76 mm     | 159mm         | 95mm          |
| RBWS1481H     | 73 mm        | 152 mm        | 38 mm         | 76 mm     | 159mm         | 95mm          |
| RBWS1481J     | 76 mm        | 152 mm        | 38 mm         | 76 mm     | 159mm         | 95mm          |

| Katalognummer | Diameter (Ø) | Length 1 (L1) | Length 2 (L2) | Width (W) | Height 1 (H1) | Height 2 (H2) |
|---------------|--------------|---------------|---------------|-----------|---------------|---------------|
| RBWS1481K     | 86 mm        | 152 mm        | 38 mm         | 76 mm     | 159mm         | 95mm          |
| RBWS1482K     | 86 mm        | 165 mm        | 38 mm         | 76 mm     | 191mm         | 108mm         |
| RBWS1482M     | 95 mm        | 165 mm        | 38 mm         | 76 mm     | 191mm         | 108mm         |
| RBWS1499D     | 54 mm        | 149 mm        | 38 mm         | 76 mm     | 140mm         | 76mm          |
| RBWS1499F     | 64 mm        | 149 mm        | 38 mm         | 76 mm     | 140mm         | 76mm          |
| RBWS1499G     | 70 mm        | 149 mm        | 38 mm         | 76 mm     | 140mm         | 76mm          |
| RBWS1499H     | 73 mm        | 149 mm        | 38 mm         | 76 mm     | 140mm         | 76mm          |
| RBWS1500A     | 41 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |
| RBWS1500C     | 48 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |
| RBWS1500D     | 54 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |
| RBWS1500E     | 57 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |
| RBWS1500F     | 64 mm        | 137 mm        | 38 mm         | 76 mm     | 124mm         | 70mm          |


## YDERLIGERE PRODUKTOPLYSNINGER

RBWS1481, RBWS1482, RBWS1499 and RBWS1500 pouring basins require one RBM2660 pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

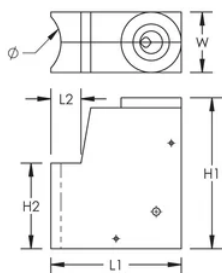

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**