

Copper-Bonded Ground Rod, Pointed

Power Utilities



FUNKTIONER

99.9% pure electrolytic copper coating

Rods have a high carbon steel core and tip that provide superior strength when driving

Copper coating will not crack when bent or tear when driven

Minimum copper coating of 10 mils on rods listed to UL® 467

nVent ERICO name, length, diameter and part number is roll-stamped within 12" (304,8 mm) of chamfered end

UL logo and control number where applicable stamped on each rod for easy inspection after installation

SPECIFIKATIONER

Table 1/1

Katalognummer	Tensile Strength	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Plating Thickness	Unit Weight	UPC Label
611330	552 MPa Min	1/2"	12.8 mm	254 µm	0.980 kg	No


YDERLIGERE PRODUKTOPLYSNINGER

For rods to be listed to UL® 467, they must be at least 8' (2.44 m) in length.

IEC® EN 62561-2 supercedes EN 50164-2.

Additional lengths available.

DIAGRAMS

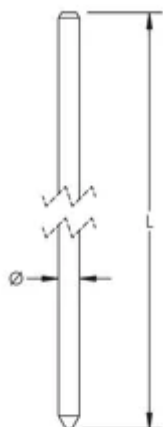

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including nickel, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE