


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 3 U, 84 HP

Power Utilities

KATALOGNUMMER

20848-611

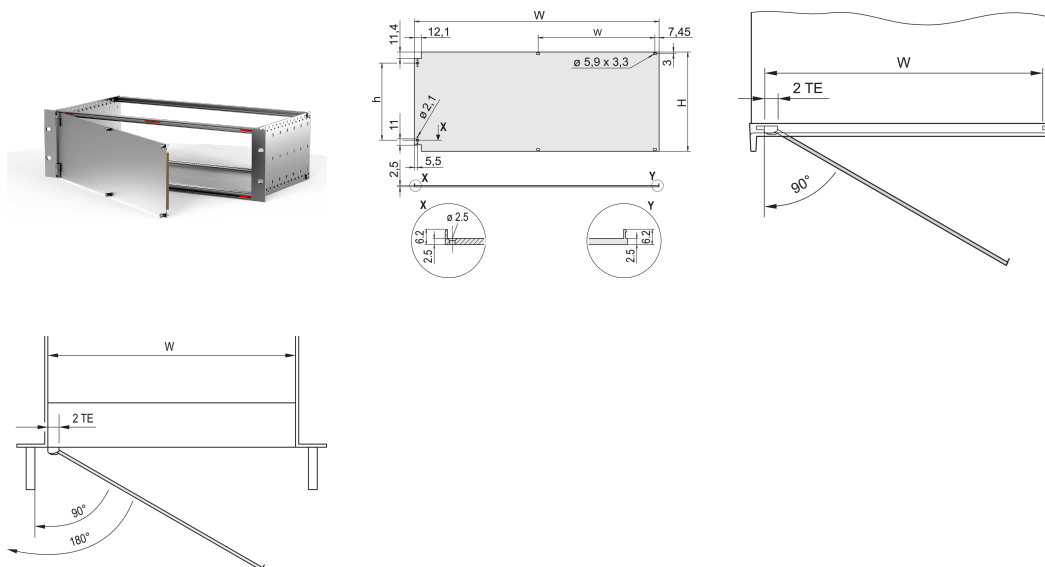

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICERINGER



FUNKTIONER

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUKTEGENSKABER

Product Type: Front Panel

Type: Front Panel without Handle

Mounting: Hinged, Side

EMC Shielding: No (Retrofittable)

Gasket Type: Textile

Materiale: Aluminium

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3 U

Højde: 128.4 mm

Rack Width: 84 HP

Bredde: 426.4 mm

Pakke mængde: 1

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE