


EuropacPRO Cover Plate for Bolting to Rugged Side Panel, 84 HP, 175 mm

Power Utilities

KATALOGNUMMER

24568-004

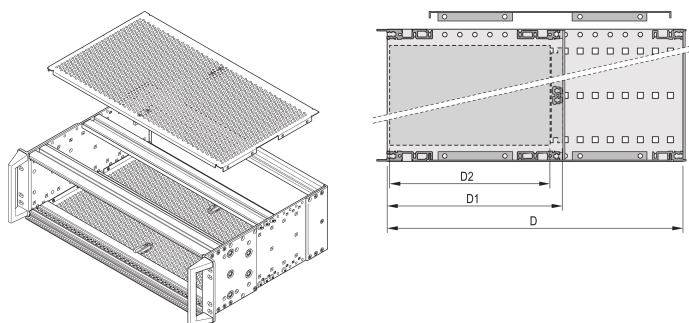

A cover plate is used for electromagnetic shielding or as mechanical protection.

CERTIFICERINGER



FUNKTIONER

Perforation degree 58%

PRODUKTEGENSKABER

Product Type: Cover Plate

Produktfamilie: EuropacPRO

Type: Perforated

Rack Width: 84 HP

Dybde: 175 mm

Pakke mængde: 1

Pakkeenhed: Pair

Torque: 2.1 N·m

YDERLIGERE PRODUKTOPLYSNINGER

A top cover locking mechanism is optionally available that also fixes the top cover in the front and rear guide rail.

4 stainless steel EMC contact strips per subrack are required for shielding, please order separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE