


LAN Surge Protector

Power Utilities

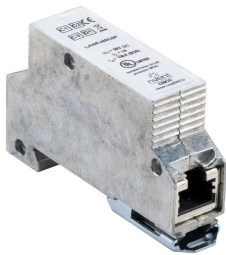

CERTIFICERINGER



FUNKTIONER

Rugged, metallic enclosure provides both environmental and electrical shielding

Up to CAT6 and POE (Power Over Ethernet) protection in one product


Simple, bi-directional installation

SPECIFIKATIONER

Katalognummer	LANRJ45C6P
Nominal System Voltage (Un)	48 VDC
Max Continuous Operating Voltage (Uc)	50 VDC
Voltage Protection Rating (VPR), L-L	150 V
Voltage Protection Rating (VPR), L-PE	550 V
Nominal Discharge Current (In), L-L	150 A 8/20 µs
Impulse Current (Iimp)	1 kA 10/350 µs

Katalognummer	LANRJ45C6P
Rated Load Current (IL)	1 A
Frequency	250 MHz Max
Temperature	-40 to 80 °C
Enclosure Rating	IP 20
Height (H)	75 mm
Width (W)	19 mm

DIAGRAMS

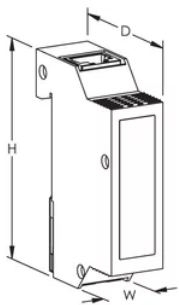

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE