

AMC Front Panel With Pull Handle



AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

CERTIFICERINGER



FUNKTIONER

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

SPECIFIKATIONER

Accessory Type: Front panel

Product Type: Front Panel


Table 1/2

Katalognummer	Højde (H)	Rack Width	Design Feature	Materiale	Finish	Pakke mængde
30849-682	73.8mm	6HP	Full-Size	Aluminium	Passivated	1
30849-670	148.8mm	4HP		Aluminium	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Aluminium	Passivated	1

Katalognummer	Højde (H)	Rack Width	Design Feature	Materiale	Finish	Pakke mængde
30849-403	73.8mm	4HP	Mid-Size	Stainless Steel		1
30849-404	73.8mm	6HP	Full-Size	Stainless Steel		1
30849-406	148.8mm	4HP	Mid-Size	Stainless Steel		1
30849-407	148.8mm	6HP	Full-Size	Stainless Steel		1
30849-402	73.8mm	3HP	Compact	Stainless Steel		1
30849-658	73.8mm	4HP	Mid-Size	Aluminium	Passivated	1

Table 2/2

Katalognummer	Front Finish	Rear Finish	Dybde (D)	Bredde (W)	Hurtigforsendelse
30849-682	Raw	Raw	2.5mm	29mm	Nej
30849-670	Raw	Raw	2.5mm	19mm	Nej
30849-694	Raw	Raw	2.5mm	29mm	Nej
30849-403	Raw	Raw	1mm	19mm	Nej
30849-404	Raw	Raw	1mm	29mm	Nej
30849-406	Raw	Raw	1mm	19mm	Nej
30849-407	Raw	Raw	1mm	29mm	Nej
30849-402	Raw	Raw	1mm	13.9mm	Nej
30849-658	Raw	Raw	2.5mm	19mm	Nej

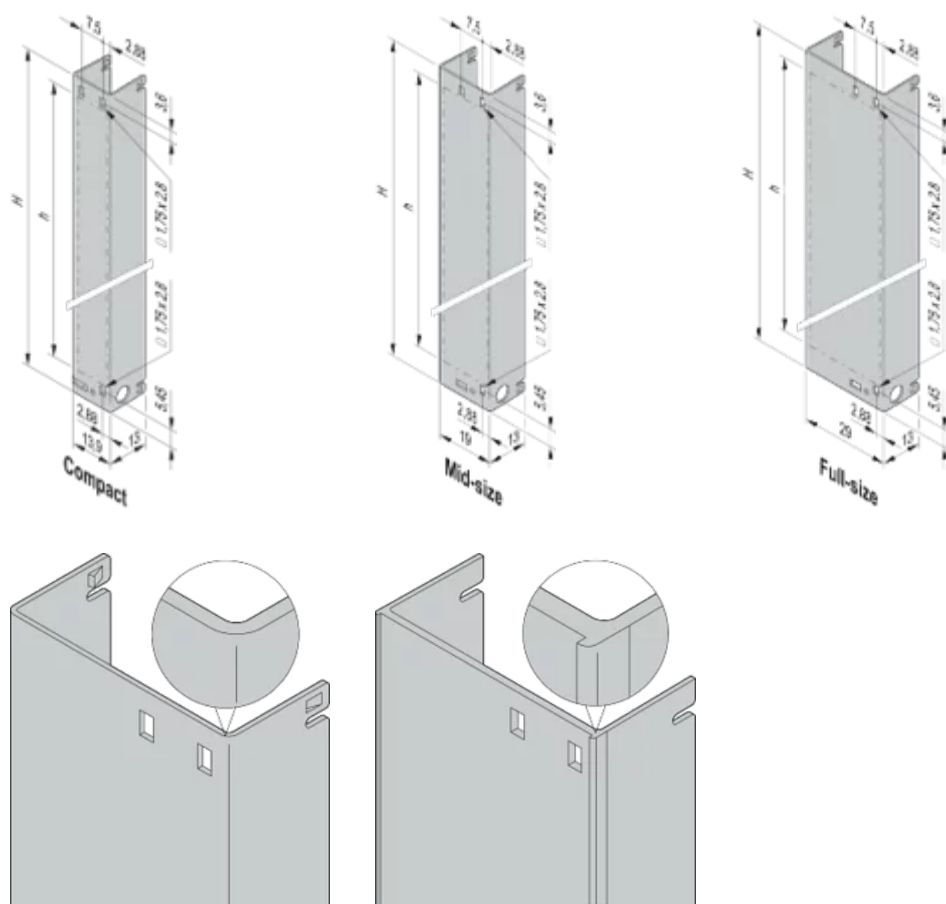

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE