


ATCA Front Panel, Al-Profile, Reinforced With Spring Loading

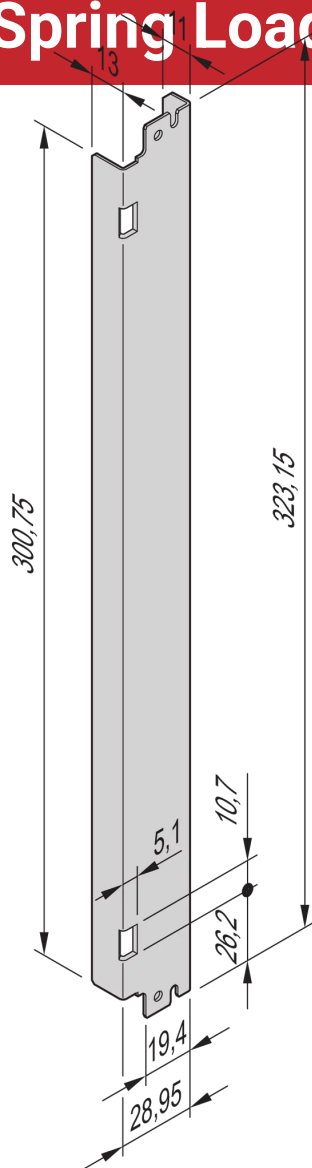

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

CERTIFICERINGER



FUNKTIONER

Configuration: Front panel with IEA handle (with/without spring loading)

Al extrusion; for mesh EMC sealing

SPECIFIKATIONER

Dybde (D):	1mm
Rack Width:	6HP
Rack Height:	8U
Materiale:	Aluminium
Accessory Type:	Front panel
Product Type:	Front Panel


Table 1/2

Katalognummer	Pakke mængde	Håndtagstype	Front Finish	Rear Finish	Finish	Højde (H)
31596-900	1	Lever	Raw	Raw	Passivated	323.15mm
31596-899	1	Plunger	Raw	Raw	Passivated	323.15mm

Table 2/2

Katalognummer	Bredde (W)	Hurtigforsendelse
31596-900	29mm	Nej
31596-899	29mm	Nej

DIAGRAMS

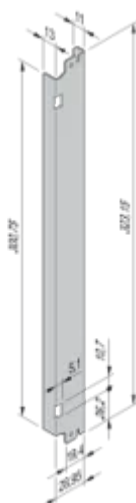

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE