


CompacPRO Complete Desktop Case, Unshielded

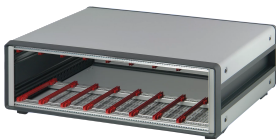

The pre-configured nVent SCHROFF CompacPRO case provides electronics protection for 19" assemblies such as plug-in units and euroboards. The aluminum die cast frame and sidepanels guarantee a robust solution. In addition an extensive accessory range is available.

CERTIFICERINGER



FUNKTIONER

Desktop case pre-configured in accordance with IEC 60297-3-101 for 19" components

Aluminum construction ensures robust solution

Side panel with integrated handle function

For backplane mounting with insulation strips

Ventilation slots in rear panel

Ventilation slots in base plate

IP 20 in accordance with IEC 60529

Front and rear identical, depth-symmetrical construction

GND / earthing connections in accordance with (please see catalog page 5.76)

Conforms with DIN EN 62368-1

SPECIFIKATIONER

Product Type:	Case
Type:	Case for 19" Components

Table 1/3

Katalognummer	Rack Height	Højde	Rack Width	Bredde	Dybde	Pakke mængde
14575-175	3U	147.1mm	84HP	471mm	331mm	1
14575-155	3U	147.1mm	63HP	364mm	331mm	1
14575-156	3U	147.1mm	63HP	364mm	391mm	1
14575-154	3U	147.1mm	63HP	364mm	271mm	1
14575-174	3U	147.1mm	84HP	471mm	271mm	1
14575-115	3U	147.1mm	28HP	186mm	331mm	1
14575-136	3U	147.1mm	42HP	257mm	391mm	1
14575-135	3U	147.1mm	42HP	257mm	331mm	1
14575-176	3U	147.1mm	84HP	471mm	391mm	1
14575-114	3U	147.1mm	28HP	186mm	271mm	1
14575-134	3U	147.1mm	42HP	257mm	271mm	1
14575-178	3U	147.1mm	84HP	471mm	511mm	1

Table 2/3

Katalognummer	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
14575-175	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-155	129.3mm	326mm	Single Piece	No	IEC 60297-3-103	No
14575-156	129.3mm	326mm	Single Piece	No	IEC 60297-3-103	No

Katalognummer	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
14575-154	129.3mm	326mm	Single Piece	No	IEC 60297-3-103	No
14575-174	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-115	129.3mm	148mm	Single Piece	No	IEC 60297-3-103	No
14575-136	129.3mm	219mm	Single Piece	No	IEC 60297-3-103	No
14575-135	129.3mm	219mm	Single Piece	No	IEC 60297-3-103	No
14575-176	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No
14575-114	129.3mm	148mm	Single Piece	No	IEC 60297-3-103	No
14575-134	129.3mm	219mm	Single Piece	No	IEC 60297-3-103	No
14575-178	129.3mm	432mm	Single Piece	No	IEC 60297-3-103	No

Table 3/3

Katalognummer	Finish	Materiale	Beskyttelsesgrad	Static Load	Hurtigforsendelse
14575-175	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-155	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-156	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-154	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-174	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-115	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-136	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-135	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej

Katalognummer	Finish	Materiale	Beskyttelsesgrad	Static Load	Hurtigforsendelse
14575-176	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-114	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-134	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej
14575-178	Anodized, Struktur Pulvermaling	Aluminium	IP20	30kg	Nej

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE