


CPCI Backplane, System Slot Right

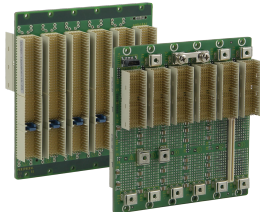

The nVent SCHROFF CompactPCI Backplanes have best in class signal integrity and MTBF values due to SMD components, ceramics capacitors and press fit connectors

CERTIFICERINGER



FUNKTIONER

In accordance with: PICMG 2.0 R3.0 CompactPCI Core specification, PICMG 2.1 R2.0 Hot Swap specification, PICMG 2.9 R1.0 System Management Bus specification, PICMG 2.10 R1.0 Keying specification

Digital GND can be connected to/isolated from chassis GND by means of screws

V(I/O) adjustable to +3.3 V or +5 V

Infeed of supply voltages via powerbugs (ring tag M4), FASTONs

Outer layers act as GND surfaces

Utility plug for status signals (SMCQ)

Multiple backplanes can be placed together without loss of slots

Outstanding high-frequency noise suppression and very high MTBF values due to ceramic capacitors

Intelligent platform management bus (IPMB) connector to PICMG 2.9

SPECIFIKATIONER

Table 1/3

Katalognummer	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
---------------	--------------	-----------------	-------------	----------------	-------------	------------

23006-331	Backplane	1	3U	CompactPCI, No Bus		4HP
23006-811	Backplane	1	3U	CompactPCI, No Bus		4HP
23006-300	Backplane	8	3U	CompactPCI, 32-bit	Right	4HP
23006-301	Backplane	5	3U	CompactPCI, 32-bit	Right	4HP
23006-303	Backplane	3	3U	CompactPCI, 32-bit	Right	4HP
23006-332	Backplane	2	3U	CompactPCI, 32-bit	Right	4HP
23006-334	Backplane	4	3U	CompactPCI, 32-bit	Right	4HP
23006-336	Backplane	6	3U	CompactPCI, 32-bit	Right	4HP
23006-337	Backplane	7	3U	CompactPCI, 32-bit	Right	4HP
23006-353	Backplane	3	3U	CompactPCI, 64-bit	Right	4HP
23006-354	Backplane	4	3U	CompactPCI, 64-bit	Right	4HP
23006-355	Backplane	5	3U	CompactPCI, 64-bit	Right	4HP
23006-358	Backplane	8	3U	CompactPCI, 64-bit	Right	4HP
23006-372	Backplane	2	6U	CompactPCI, 64-bit	Right	4HP
23006-373	Backplane	3	6U	CompactPCI, 64-bit	Right	4HP
23006-374	Backplane	4	6U	CompactPCI, 64-bit	Right	4HP
23006-375	Backplane	5	6U	CompactPCI, 64-bit	Right	4HP
23006-376	Backplane	6	6U	CompactPCI, 64-bit	Right	4HP
23006-377	Backplane	7	6U	CompactPCI, 64-bit	Right	4HP

23006-378	Backplane	8	6U	CompactPCI, 64-bit	Right	4HP
23006-812	Backplane	2	3U	CompactPCI, 32-bit	Right	4HP
23006-813	Backplane	3	3U	CompactPCI, 32-bit	Right	4HP
23006-814	Backplane	4	3U	CompactPCI, 32-bit	Right	4HP
23006-815	Backplane	5	3U	CompactPCI, 32-bit	Right	4HP
23006-816	Backplane	6	3U	CompactPCI, 32-bit	Right	4HP
23006-817	Backplane	7	3U	CompactPCI, 32-bit	Right	4HP
23006-818	Backplane	8	3U	CompactPCI, 32-bit	Right	4HP
23006-833	Backplane	3	3U	CompactPCI, 64-bit	Right	4HP
23006-834	Backplane	4	3U	CompactPCI, 64-bit	Right	4HP
23006-835	Backplane	5	3U	CompactPCI, 64-bit	Right	4HP
23006-838	Backplane	8	3U	CompactPCI, 64-bit	Right	4HP
23006-862	Backplane	2	6U	CompactPCI, 64-bit	Right	4HP
23006-863	Backplane	3	6U	CompactPCI, 64-bit	Right	4HP
23006-864	Backplane	4	6U	CompactPCI, 64-bit	Right	4HP
23006-865	Backplane	5	6U	CompactPCI, 64-bit	Right	4HP
23006-866	Backplane	6	6U	CompactPCI, 64-bit	Right	4HP
23006-867	Backplane	7	6U	CompactPCI, 64-bit	Right	4HP
23006-868	Backplane	8	6U	CompactPCI, 64-bit	Right	4HP

Table 2/3

Katalognummer	Voltage I/O	Connector Type	Power Connector Type	Utility Connector Type	Bredde	Pakke mængde
23006-331	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs		19.32mm	1
23006-811	5V	HM 2.0	Power Bugs for M4 Cable Lugs		19.32mm	1
23006-300	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-301	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1
23006-303	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-332	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.64mm	1
23006-334	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-336	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	121.01mm	1
23006-337	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	141.24mm	1
23006-353	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-354	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-355	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1
23006-358	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-372	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.64mm	1
23006-373	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-374	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-375	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1

Katalognummer	Voltage I/O	ConnectorType	Power ConnectorType	Utility ConnectorType	Bredde	Pakke mængde
23006-376	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	121.01mm	1
23006-377	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	141.24mm	1
23006-378	3.3V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-812	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.64mm	1
23006-813	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-814	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-815	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1
23006-816	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	121.01mm	1
23006-817	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	141.24mm	1
23006-818	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-833	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-834	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-835	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1
23006-838	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-862	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	39.64mm	1
23006-863	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	60.05mm	1
23006-864	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	80.28mm	1
23006-865	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	100.59mm	1

Katalognummer	Voltage I/O	ConnectorType	Power ConnectorType	Utility ConnectorType	Bredde	Pakke mængde
23006-866	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	121.01mm	1
23006-867	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	141.24mm	1
23006-868	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1

Table 3/3

Katalognummer	Hurtigforsendelse
23006-331	Nej
23006-811	Nej
23006-300	Nej
23006-301	Nej
23006-303	Nej
23006-332	Nej
23006-334	Nej
23006-336	Nej
23006-337	Nej
23006-353	Nej
23006-354	Nej
23006-355	Nej
23006-358	Nej
23006-372	Nej

Katalognummer	Hurtigforsendelse
23006-373	Nej
23006-374	Nej
23006-375	Nej
23006-376	Nej
23006-377	Nej
23006-378	Nej
23006-812	Nej
23006-813	Nej
23006-814	Nej
23006-815	Nej
23006-816	Nej
23006-817	Nej
23006-818	Nej
23006-833	Nej
23006-834	Nej
23006-835	Nej
23006-838	Nej
23006-862	Nej

Katalognummer	Hurtigforsendelse
23006-863	Nej
23006-864	Nej
23006-865	Nej
23006-866	Nej
23006-867	Nej
23006-868	Nej

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE