


CPCI Backplane

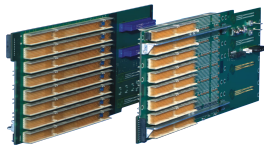

The nVent SCHROFF CompactPCI Backplanes have best in class signal integrity and MTBF values due to SMD components, ceramics capacitors and press fit connectors.

CERTIFICERINGER



FUNKTIONER

Digital GND can be connected to/isolated from chassis GND by means of screws

V(I/O) can be set to +3.3 V or +5 V

Outer layers act as GND surfaces

Utility plug for status signals (SMCQ)

Outstanding high frequency noise suppression and very high MTBF values due to ceramic capacitors

Intelligent platform management bus (IPMB) connector to PICMG 2.9

SPECIFIKATIONER

Table 1/3

Katalognummer	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
23006-792	Backplane	2	7U	CompactPCI, 64-bit	Left	4HP
23006-793	Backplane	2	7U	CompactPCI, 64-bit	Left	4HP

Katalognummer	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
23006-794	Backplane	2	9U	CompactPCI, 64-bit	Left	4HP
23006-799	Backplane	4	7U	CompactPCI, 64-bit	Left	4HP
23006-798	Backplane	6	7U	CompactPCI, 64-bit	Left	4HP
23006-601	Backplane	8	6U	CompactPCI, 64-bit, H.110 Bus	Right	4HP
23006-611	Backplane	8	9U	CompactPCI, 64-bit, PSB, H.110 Bus	Left	4HP
23006-795	Backplane	4	7U	CompactPCI, 64-bit	Left	4HP
23006-796	Backplane	6	9U	CompactPCI, 64-bit	Left	4HP
23006-797	Backplane	8	9U	CompactPCI, 64-bit	Left	4HP

Table 2/3

Katalognummer	Voltage I/O	Connector Type	Power Connector Type	Utility Connector Type	Bredde	Pakke mængde
23006-792	5V	HM 2.0	ATX (male) Connector		39.64mm	1
23006-793	5V	HM 2.0	Mini-fit 10-pin	SMCQ, 12-pin	39.64mm	1
23006-794	5V	HM 2.0	(1) P47	SMCQ, 12-pin	39.64mm	1
23006-799	5V	HM 2.0	Mini-fit 24-pin	SMCQ, 12-pin		1
23006-798	5V	HM 2.0	Mini-fit 24-pin	SMCQ, 12-pin	121mm	1
23006-601	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-611	5V	HM 2.0	(2) P47	SMCQ, 12-pin	161.56mm	1

Katalognummer	Voltage I/O	ConnectorType	Power ConnectorType	Utility ConnectorType	Bredde	Pakke mængde
23006-795	5V	HM 2.0	(2) P47	SMCQ, 12-pin		1
23006-796	5V	HM 2.0	(2) P47	SMCQ, 12-pin	121mm	1
23006-797	5V	HM 2.0	(2) P47	SMCQ, 12-pin	161.56mm	1

Table 3/3

Katalognummer	Hurtigforsendelse
23006-792	Nej
23006-793	Nej
23006-794	Nej
23006-799	Nej
23006-798	Nej
23006-601	Nej
23006-611	Nej
23006-795	Nej
23006-796	Nej
23006-797	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Other configurations available on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl,

materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE