


CPCI Power Backplane With P 47 Connector

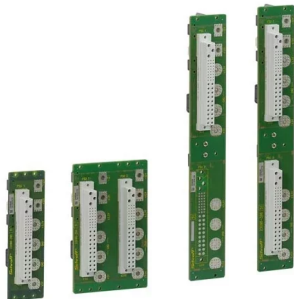

Power Backplane for CompactPCI Applications. With P47 Power Connector.

CERTIFICERINGER



FUNKTIONER

In accordance with: PICMG 2.11 R1.0 CompactPCI Power Interface specification

In accordance with: PICMG 2.9 R1.0 System Management Bus specification

Single, parallel or redundant operation possible

Geographical address adjustable

Power supply over crimp contacts inserted into the plug, no supply voltage on the backplane

Power cable available as an accessory

DC outlets with powerbugs for extremely low drops in voltage

SPECIFIKATIONER

Table 1/2

Katalognummer	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-393	Backplane	1	3U	CompactPCI Power Backplane with P47	8HP	

Katalognummer	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-394	Backplane	2	3U	CompactPCI Power Backplane with P47	8HP	P47
23098-395	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	
23098-396	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	

Table 2/2

Katalognummer	Power Connector Type	Utility Connector Type	Bredde	Pakke mængde	Hurtigforsendelse
23098-393	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	Nej
23098-394	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	80.3mm	1	Nej
23098-395	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	Nej
23098-396	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	Nej

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE