


Double Test Socket, Ø 2 mm

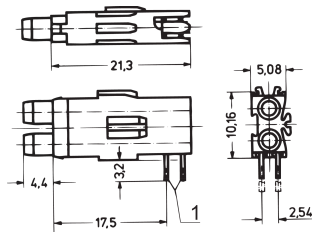

Double test sockets for mounting plane 1 and 2, short and long type.

Solder temperature should only be applied for a maximum of 5 seconds. The plastic body should be protected from the solder wave when wave soldering.

CERTIFICERINGER



FUNKTIONER

Double test sockets for Front Element System

SPECIFIKATIONER

Diameter: 2mm
Product Type: Socket

Table 1/2

Katalognummer	Type	Pakke mængde	Spænding AC	Maksimal strøm	Test Voltage @ 50 Hz	Omgivelsestemperatur
69004-089	Long, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-131	Short, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-090	Long, Mounting Plane 2	10	30V	1A	1kV	-25 to 70°C

Table 2/2

Katalognummer	Solder Temperature	Flammability Rating	Hurtigforsendelse
---------------	--------------------	---------------------	-------------------

69004-089	260°C	UL® 94V-0	Nej
69004-131	260°C	UL® 94V-0	Nej
69004-090	260°C	UL® 94V-0	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE