


VME64x System, Tower, 5 U, Pluggable PSU

KATALOGNUMMER

10836-045

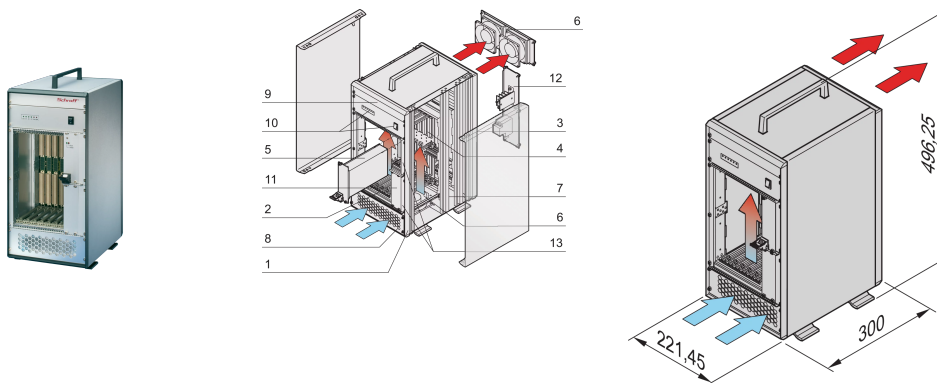

VME64 tower system for 7 VME64x boards 6 U, 160 mm. The power for the system is created by a pluggable power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICERINGER



FUNKTIONER

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

Pluggable PSU, 19" form factor, 300 W; a second PSU can optionally be fitted

Backplane VME64x 7 slot, 6 U, J1/J2 monolithic without P0 connector, Rear I/O option, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 2 fans, cooling from front to rear side; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep and Rear I/O option

Display module for DC operating voltages, fan and temperature alarm

Option to mount a 5.25" DVD drive unit

PRODUKTEGENSKABER

Product Type: System

Number of Slots: 7

Type: Tower

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Indgangsspænding AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 10U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Yes

Rear I/O: Yes

Complies With: ANSI/VITA 1.1-1997

Pakke mængde: 1

YDERLIGERE PRODUKTOPLYSNINGER

Modified systems available on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE