


MTCA.4 Cube System for 7 Double AMC Modules, 5 U, 42 HP

KATALOGNUMMER

11850-021

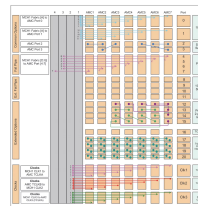

The system is designed for development and lab testing work. The hot-swap fan module with EMMC ensures that the front and rear slots are properly cooled at a low noise level. The fan speed is controlled independently for front and rear and is set via the MCH. The backplane features clock and trigger lines per PICMG MTCA.4, as well as interlocks. It also provides direct connections for SAS/SATA and lines between the AMCs.

CERTIFICERINGER



FUNKTIONER

In accordance with PICMG MTCA.4 R1.0 specification

5 U, 42 HP cube system for 6 Double Mid-Size and 1 Double Full-Size AdvancedMC modules, 1 Double Full-Size MCH and 1 Double Full-Size power module

6 rear transition module slots for Double Mid-Size modules and one slot for Double Full-Size

Backplane with star topology, direct connections for S-ATA/SAS, clock and trigger lines per PICMG MTCA.4

Clock topology per PICMG AMC.0 R2.0

Hot-swap fan module with cooling unit manager (CU EMMC), airflow from bottom to top, fan speed for front and rear sections can be separately adjusted via MCH

Air filter accessible from the front

PRODUKTEGENSKABER

Product Type: System

Number of Slots: 7

Type: Half 19" Rack Mount

Backplane Type: MTCA.4 Star Topology

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 80W

Airflow Direction: Bottom to Top

Rack Height: 5U

Power Supply Type: (1) Double Full-size PM

Power Supply Included: No

Rear I/O: Yes

Complies With: PICMG MTCA.4 R1.0

Dybde: 373.3mm

Højde: 222.25mm

Pakke mængde: 1

YDERLIGERE PRODUKTOPLYSNINGER

Modified systems available on request.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE