


Eurorack 19" Panel/Slide Mount, 38 U, AlZn

KATALOGNUMMER

22117-356

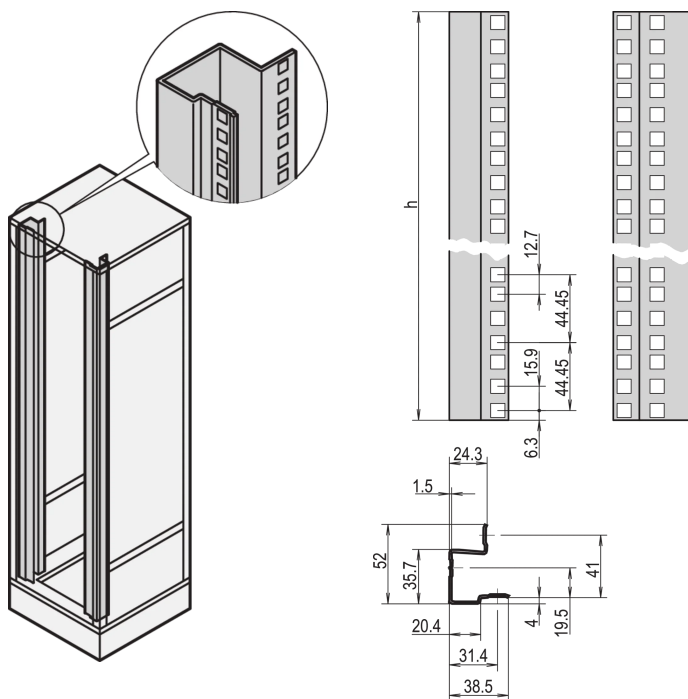

Slide mount with adjustable increments.

CERTIFICERINGER



FUNKTIONER

For depth-adjustable mounting

St, 1.5 mm, with EIA cut-out

For the assembly of a third 19" plane 1 pair of 19" panel/slide mounts and 2 pairs of depth members are needed

PRODUKTEGENSKABER

Rack Height: 38U

Materiale: Stål

Finish: Aluminum-Zinc Plated

Pakke mængde: 2

Højde: 1798mm

Produktfamilie: Eurorack

Product Type: Slide Mount

Type: 19" Panel Slide Mount

Net Weight: 4.25kg

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE