


Eurorack Slide Rail, 40 kg, Depth-Adjustable

KATALOGNUMMER

28127-001

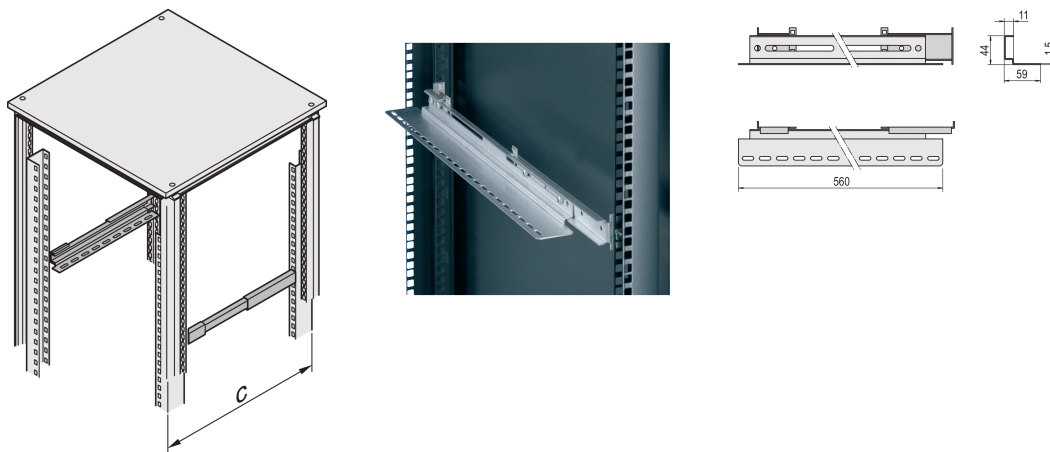

Eurorack Slide Rail with 40 kg load capacity for mounting on the cabinet uprights or 19" panel/slide mounts. The slide rail supports shelf of heavy 19" Chassis.

CERTIFICERINGER



FUNKTIONER

Can be fitted in 1 U increments

Static load-carrying capacity 40 kg per pair, depth-adjustable

St, 1.5 mm, finish AlZn

For fitting to 19" panel/slide mounts or 19" server panel/slide mounts (pitch c from 675 mm to 850 mm)

Support for heavy 19" modules

Wide support surface

PRODUKTEGENSKABER

Product Type: Slide Rail

Produktfamilie: Eurorack

Materiale: Stål

Finish: Aluminum-Zinc Plated

Length: 560mm

Static Load: 40kg

Pakke mængde: 1

YDERLIGERE PRODUKTOPLYSNINGER

For rack-mounting from 800 mm depth only.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE