 


EuropacPRO 19" Subrack Kit for Backplane, Heavy, Shielded, Front Handle

EMC Shielded subrack for backplane mounting, heavy version with tox welded side panels and front handle.



CERTIFICERINGER



FUNKTIONER

Subrack with side panel type H ("Heavy"), 19" bracket is firmly fixed to side panel (tox-cold welded) and includes handles

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

Rear horizontal rail for backplane mounting with insulation strip

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Shock and vibration tested to the German "Bahn" standards BN 411002, BN 411003

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

IP 20, in accordance with IEC 60529

SPECIFIKATIONER

Materiale: Aluminium

Finish: Anodized; Passivated

Product Type: Subrack/Chassis

EMC Shielding: Yes

Table 1/3

Katalognummer	Rack Height	Dybde (D)	Pakke mængde	For Mounting	Board Depth	EMC Gasket Type
24567-172	3U	235mm	1	Backplane	160mm, 220mm	Textile
24567-173	3U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile
24567-174	3U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile
24567-472	6U	235mm	1	Backplane	160mm, 220mm	Textile
24567-473	6U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile
24567-474	6U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile

Table 2/3

Katalognummer	Shock and Vibration Tolerance	Håndtag inkluderet	Mounting	Complies With	Rack Width	Static Load
24567-172	5g (force)	Yes	Rack	IEC 60297-3-103	84HP	15kg
24567-173	5g (force)	Yes	Rack	IEC 60297-3-103	84HP	15kg
24567-174	5g (force)	Yes	Rack	IEC 60297-3-103	84HP	15kg
24567-472	5g (force)	Yes	Rack	IEC 60297-3-103	84HP	15kg
24567-473	5g (force)	Yes	Rack	IEC 60297-3-103	84HP	15kg
24567-474	5g (force)	Yes	Rack	IEC 60297-3-103	84HP	15kg

Table 3/3


Katalognummer	Hurtigforsendelse
---------------	-------------------

24567-172	Nej
24567-173	Nej
24567-174	Nej
24567-472	Nej
24567-473	Nej
24567-474	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

DIAGRAMS

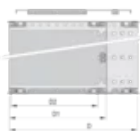

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE