


# EuropacPRO Advanced EMC 45 Top and Bottom Covers, Screwed to Side Panel, Ø 2.3mm

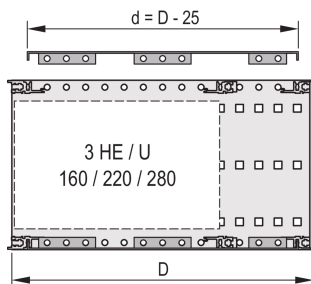

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

## CERTIFICERINGER



## FUNKTIONER

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1, perforation diameter Ø 2.3mm, degree 50%

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

## SPECIFIKATIONER

<b>Materiale:</b>	Aluminium
<b>Product Type:</b>	Cover Plate
<b>Produktfamilie:</b>	EuropacPRO
<b>Finish:</b>	Passivated
<b>Type:</b>	Perforated
<b>Works With:</b>	Subracks

Table 1/1

Katalognummer	Rack Width	Dybde	Pakke mængde	Pakkeenhed	Hurtigforsendelse
---------------	------------	-------	--------------	------------	-------------------

24563-555	36HP	175mm	2	Pair	Nej
24563-556	36HP	235mm	2	Pair	Nej
24563-560	42HP	175mm	2	Pair	Nej
24563-561	42HP	235mm	2	Pair	Nej
24563-562	42HP	275mm	2	Pair	Nej
24563-563	42HP	277.75mm	2	Pair	Nej
24563-564	42HP	295mm	2	Pair	Nej
24563-660	63HP	175mm	2	Pair	Nej
24563-661	63HP	235mm	2	Pair	Nej
24563-662	63HP	275mm	2	Pair	Nej
24563-663	63HP	295mm	2	Pair	Nej
24563-760	84HP	175mm	2	Pair	Nej
24563-761	84HP	235mm	2	Pair	Nej
24563-762	84HP	275mm	2	Pair	Nej
24563-763	84HP	277.75mm	2	Pair	Nej
24563-764	84HP	295mm	2	Pair	Nej
24563-765	84HP	355mm	2	Pair	Nej
24563-766	84HP	415mm	2	Pair	Nej
24563-767	84HP	495mm	2	Pair	Nej

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unndladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**