


EuropacPRO Advanced EMC Plus, Dual Mesh Top and Bottom Covers, Screwed to Side Panel

NEW PRODUCT

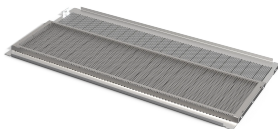

A cover plate is used for electromagnetic shielding and as mechanical protection. The cover can be screwed onto the side panel.

FUNKTIONER

Dual mesh top and bottom covers with EMC and airflow optimized perforation, for highest RF-shielding requirements

Fulfills the requirements of the fire safety standard EN 62368-1

For PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

SPECIFIKATIONER

Materiale:	Aluminium
Product Type:	Cover Plate
Produktfamilie:	EuropacPRO
Finish:	Passivated
Type:	Perforated
Works With:	Subracks

Table 1/1

Katalognummer	Dybde	Pakke mængde	Rack Width	Board Depth	Pakkeenhed	Hurtigforsendelse
24563-770	175mm	2	84HP	160mm	Pair	Nej
24563-771	235mm	2	84HP	160mm	Pair	Nej

Katalognummer	Dybde	Pakke mængde	Rack Width	Board Depth	Pakkeenhed	Hurtigforsendelse
24563-772	275mm	2	84HP	160mm	Pair	Nej
24563-773	277.75mm	2	84HP	160mm	Pair	Nej
24563-774	295mm	2	84HP	160mm	Pair	Nej
24563-775	355mm	2	84HP	160mm	Pair	Nej
24563-776	415mm	2	84HP	160mm	Pair	Nej
24563-777	475mm	2	84HP	160mm	Pair	Nej
24563-780	235mm	2	84HP	220mm	Pair	Nej
24563-781	295mm	2	84HP	220mm	Pair	Nej
24563-782	355mm	2	84HP	220mm	Pair	Nej
24563-783	415mm	2	84HP	220mm	Pair	Nej
24563-784	475mm	2	84HP	220mm	Pair	Nej
24563-790	295mm	2	84HP	280mm	Pair	Nej
24563-791	355mm	2	84HP	280mm	Pair	Nej
24563-792	415mm	2	84HP	280mm	Pair	Nej
24563-793	475mm	2	84HP	280mm	Pair	Nej

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE