


Front Handle One-Piece, Width 12.2 mm

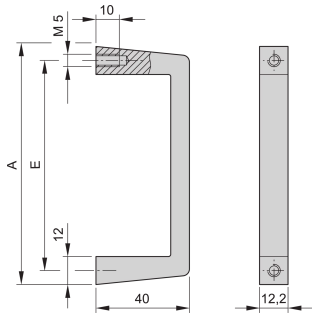

The handle can be assembled to a subrack or 19" front panel. Available with clear or black anodized surface. Handles will be bolted from the rear side.

CERTIFICERINGER



FUNKTIONER

Static load-carrying capacity 30 kg/pair

Bolted from rear

SPECIFIKATIONER

Materiale:	Aluminium
Produktfamilie:	EuropacPRO
Product Type:	Handle
Works With:	Subracks

Table 1/2

Katalognummer	Rack Height	Finish	Pakke mængde	Håndtagstype	Farve	Torque
10501-116	1U	Anodized	1	Straight	Silver	
10501-016	2U	Anodized	1	Straight	Silver	

Katalognummer	Rack Height	Finish	Pakke mængde	Håndtagstype	Farve	Torque
10501-004	2U	Anodized	1	Straight	Silver	
10501-025	2U	Anodized	1	Straight	Black	
10501-005	3U	Anodized	1	Straight	Silver	2.4N·m
10501-020	3U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-026	3U	Anodized	1	Straight	Black	2.4N·m
10501-006	4U	Anodized	1	Straight	Silver	
10501-018	4U	Anodized	1	Straight	Silver	2.4N·m
10501-021	4U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-027	4U	Anodized	1	Straight	Black	
10501-007	5U	Anodized	1	Straight	Silver	
10501-028	5U	Anodized	1	Straight	Black	
10501-022	6U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-008	6U	Anodized	1	Straight	Silver	2.4N·m
10501-029	6U	Anodized	1	Straight	Black	2.4N·m

Table 2/2

Katalognummer	Hurtigforsendelse
10501-116	Nej
10501-016	Nej
10501-004	Nej

Katalognummer	Hurtigforsendelse
10501-025	Nej
10501-005	Nej
10501-020	Nej
10501-026	Nej
10501-006	Nej
10501-018	Nej
10501-021	Nej
10501-027	Nej
10501-007	Nej
10501-028	Nej
10501-022	Nej
10501-008	Nej
10501-029	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please order assembly part kit separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE