

Front Panel, Anodized, Unshielded, Screw Assembly

Anodized front panel, unshielded version, Al, 2.5 mm.



CERTIFICERINGER



FUNKTIONER

Partial width front panel, Al, 2.5 mm

Al, anodized

SPECIFIKATIONER

Dybde (D):	2.5mm
Materiale:	Aluminium
Finish:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/3

Katalognummer	Rack Height	Rack Width	Pakke mængde	Mounting	Front Finish	Rear Finish
30807-508	3U	3HP	1	Screw-on Front	Anodized	Anodized

Katalognummer	Rack Height	Rack Width	Pakke mængde	Mounting	Front Finish	Rear Finish
30807-481	3U	4HP	1	Screw-on Front	Anodized	Anodized
30818-741	6U	2HP	1	Screw-on Front	Anodized	Anodized
30807-510	3U	5HP	1	Screw-on Front	Anodized	Anodized
30807-482	3U	6HP	1	Screw-on Front	Anodized	Anodized
30807-509	3U	7HP	1	Screw-on Front	Anodized	Anodized
30807-484	3U	8HP	1	Screw-on Front	Anodized	Anodized
30807-483	3U	10HP	1	Screw-on Front	Anodized	Anodized
30807-777	6U	5HP	1	Screw-on Front	Anodized	Anodized
30807-485	3U	12HP	1	Screw-on Front	Anodized	Anodized
30807-752	6U	6HP	1	Screw-on Front	Anodized	Anodized
30807-501	3U	14HP	1	Screw-on Front	Anodized	Anodized
30807-833	6U	7HP	1	Screw-on Front	Anodized	Anodized
30807-779	6U	8HP	1	Screw-on Front	Anodized	Anodized
30807-487	3U	21HP	1	Screw-on Front	Anodized	Anodized
30807-753	6U	10HP	1	Screw-on Front	Anodized	Anodized
30807-755	6U	12HP	1	Screw-on Front	Anodized	Anodized
30807-496	3U	28HP	1	Screw-on Front	Anodized	Anodized
30807-758	6U	14HP	1	Screw-on Front	Anodized	Anodized

Katalognummer	Rack Height	Rack Width	Pakke mængde	Mounting	Front Finish	Rear Finish
30807-780	6U	16HP	1	Screw-on Front	Anodized	Anodized
30807-494	3U	42HP	1	Screw-on Front	Anodized	Anodized
30807-757	6U	21HP	1	Screw-on Front	Anodized	Anodized
30807-416	2U	84HP	1	Screw-on Front	Anodized	Anodized
30807-766	6U	28HP	1	Screw-on Front	Anodized	Anodized
30808-067	3U	63HP	1	Screw-on Front	Anodized	Anodized
30807-506	3U	84HP	1	Screw-on Front	Anodized	Anodized
30807-764	6U	42HP	1	Screw-on Front	Anodized	Anodized
30807-596	4U	84HP	1	Screw-on Front	Anodized	Anodized
30807-771	6U	63HP	1	Screw-on Front	Anodized	Anodized
30807-776	6U	84HP	1	Screw-on Front	Anodized	Anodized
30807-778	6U	4HP	1	Screw-on Front	Anodized	Anodized
30810-432	3U	2HP	1	Screw-on Front	Anodized	Anodized

Table 2/3

Katalognummer	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)	Certificeringer
30807-508	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	14.9mm	RoHS
30807-481	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	20mm	RoHS
30818-741	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	9.8mm	RoHS

Katalognummer	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)	Certificeringer
30807-510	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	25mm	RoHS
30807-482	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	30.1mm	RoHS
30807-509	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	35.2mm	RoHS
30807-484	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	40.3mm	RoHS
30807-483	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	50.5mm	RoHS
30807-777	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	25mm	RoHS
30807-485	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	60.6mm	RoHS
30807-752	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	30.1mm	RoHS
30807-501	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	70.8mm	RoHS
30807-833	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	35.2mm	RoHS
30807-779	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	40.3mm	RoHS
30807-487	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	106.3mm	RoHS
30807-753	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	50.5mm	RoHS
30807-755	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	60.6mm	RoHS

Katalognummer	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)	Certificeringer
30807-496	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	141.9mm	RoHS
30807-758	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	70.8mm	RoHS
30807-780	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	80.9mm	RoHS
30807-494	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	213mm	RoHS
30807-757	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	106.3mm	RoHS
30807-416	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	84mm	426.4mm	RoHS
30807-766	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	141.9mm	RoHS
30808-067	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	319.7mm	RoHS
30807-506	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	426.4mm	RoHS
30807-764	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	213mm	RoHS
30807-596	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	426.4mm	
30807-771	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	319.7mm	RoHS
30807-776	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	426.4mm	RoHS
30807-778	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	20mm	RoHS

Katalognummer	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)	Certificeringer
30810-432	Yes	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	9.8mm	RoHS

Table 3/3


Katalognummer	Hurtigforsendelse
30807-508	Nej
30807-481	Nej
30818-741	Nej
30807-510	Nej
30807-482	Nej
30807-509	Nej
30807-484	Nej
30807-483	Nej
30807-777	Nej
30807-485	Nej
30807-752	Nej
30807-501	Nej
30807-833	Nej
30807-779	Nej
30807-487	Nej

Katalognummer	Hurtigforsendelse
30807-753	Nej
30807-755	Nej
30807-496	Nej
30807-758	Nej
30807-780	Nej
30807-494	Nej
30807-757	Nej
30807-416	Nej
30807-766	Nej
30808-067	Nej
30807-506	Nej
30807-764	Nej
30807-596	Nej
30807-771	Nej
30807-776	Nej
30807-778	Nej
30810-432	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

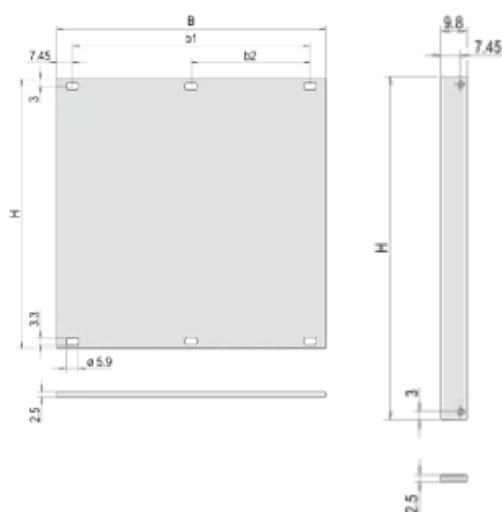

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE