


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

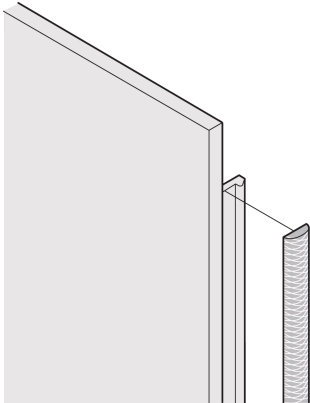

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

CERTIFICERINGER



FUNKTIONER

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

SPECIFIKATIONER

Works With:	Subracks; Cases; Front Panels
Produktfamilie:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit
Product Type:	Shielding Kit
Materiale:	Thermoplastik Halogenfri

Table 1/2

Katalognummer	Rack Height	Pakke mængde	Dybde (D)	Højde (H)	Bredde (W)	Flammability Rating
---------------	-------------	--------------	-----------	-----------	------------	---------------------

21101-978	5U	10				
21101-857	2U	10	1.62mm	52mm	3.8mm	UL® 94V-0
21101-853	3U	10	1.62mm	97mm	3.8mm	UL® 94V-0
21101-858	4U	10				
21101-854	3U	100	1.62mm	97mm	3.8mm	UL® 94V-0
21101-855	6U	10	1.62mm	232mm	3.8mm	UL® 94V-0
21101-856	6U	100	1.62mm	232mm	3.8mm	UL® 94V-0
21101-904	9U	100				
21101-859	9U	10	1.62mm	365.5mm	3.8mm	UL® 94V-0


Table 2/2

Katalognummer	Hurtigforsendelse
21101-978	Nej
21101-857	Nej
21101-853	Nej
21101-858	Nej
21101-854	Nej
21101-855	Nej
21101-856	Nej
21101-904	Nej
21101-859	Nej

YDERLIGERE PRODUKTOPLYSNINGER

EMC gaskets (textile) are required for shielding the front panels.

DIAGRAMS

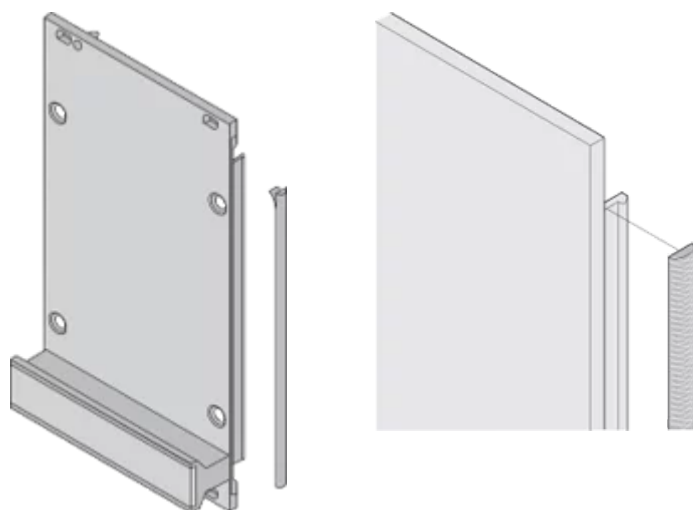

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE