


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

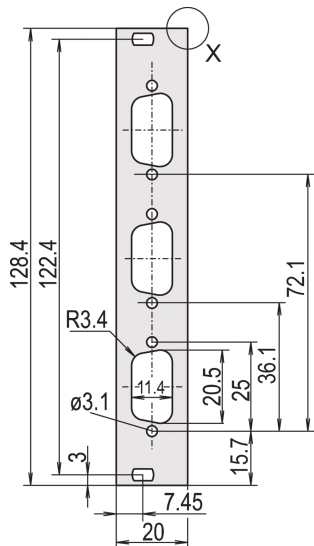

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICERINGER



FUNKTIONER

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

SPECIFIKATIONER

Rack Height:	3U
Rack Width:	4HP
Materiale:	Aluminium
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel

Type: Front Panel without Handle

EMC Shielding: No (Retrofittable)

Table 1/2

Katalognummer	Pakke mængde	Mounting	EMC Gasket Type	Front Finish	Rear Finish	Number of Pins
30118-348	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(1) 9
30118-349	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(1) 15
30118-350	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(1) 25
30118-351	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(2) 9
30118-352	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(2) 15
30118-353	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(2) 25
30118-354	1	Screw-on Front	Stainless Steel	Anodized	Conductive	(3) 9

Table 2/2

Katalognummer	Treated Edges	Complies With	Dybde (D)	Højde (H)	Bredde (W)	Hurtigforsendelse
30118-348	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej
30118-349	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej
30118-350	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej
30118-351	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej
30118-352	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej
30118-353	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej

Katalognummer	Treated Edges	Complies With	Dybde (D)	Højde (H)	Bredde (W)	Hurtigforsendelse
30118-354	No	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

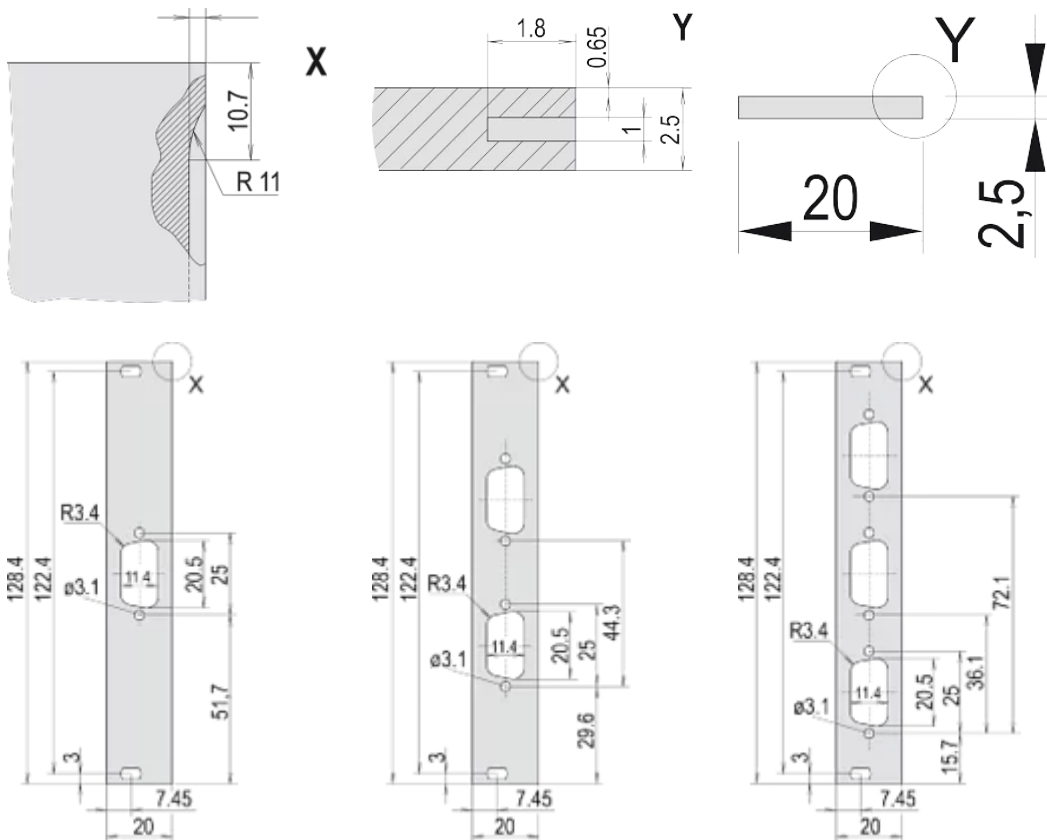

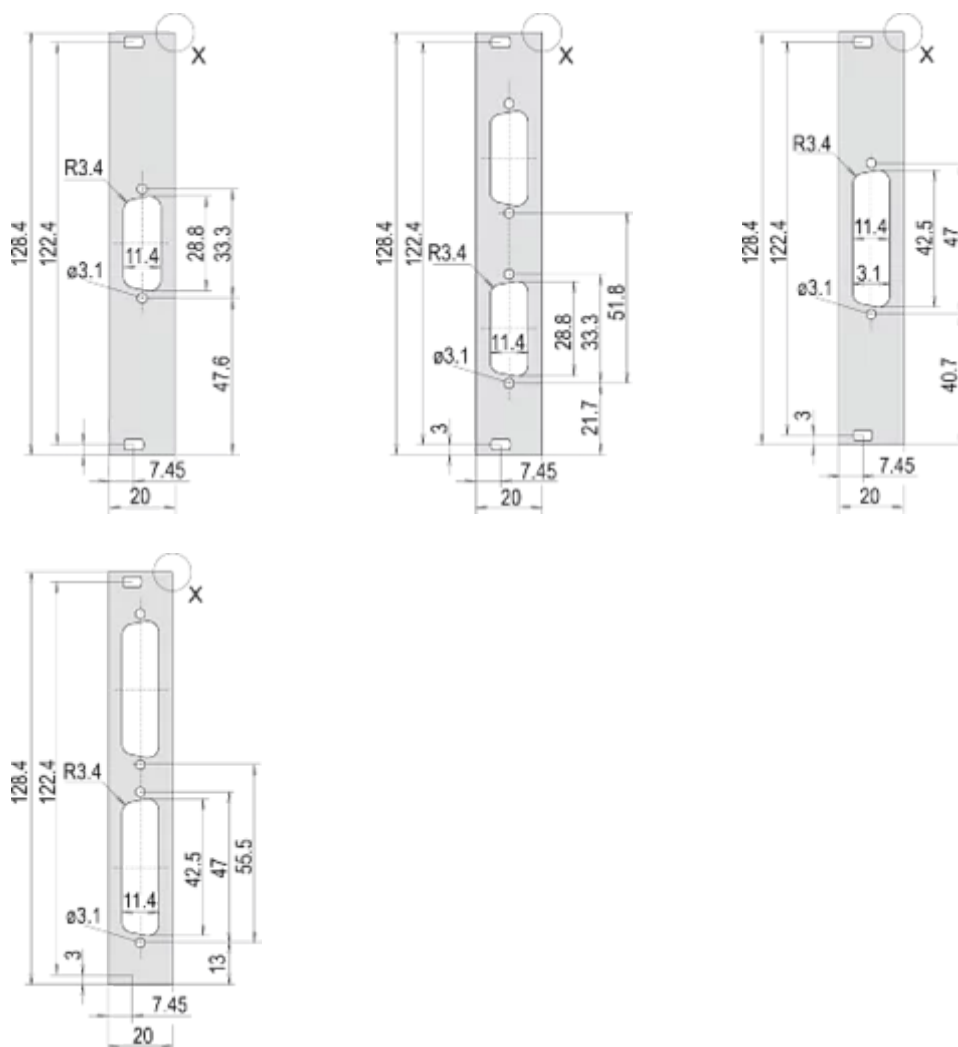

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, potentielle skader, skuldetilstand, personskader eller dødsfald og/eller materielle skader. Se www.nvent.com for yderligere oplysninger.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE