

Front Panel, Unshielded, Bottom Hinged

Unshielded front panel bottom hinged.



CERTIFICERINGER



FUNKTIONER

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFIKATIONER

Dybde (D):	2.5mm
Materiale:	Aluminium
Finish:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/2

Katalognummer	Rack Height	Rack Width	Pakke mængde	Mounting	Front Finish	Rear Finish
20838-280	3U	28HP	1	Hinged, Bottom	Anodized	Conductive
20838-271	3U	42HP	1	Hinged, Bottom	Anodized	Conductive

Katalognummer	Rack Height	Rack Width	Pakke mængde	Mounting	Front Finish	Rear Finish
20838-272	3U	63HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3U	84HP	1	Hinged, Bottom	Anodized	Conductive
20838-277	4U	42HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4U	63HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4U	84HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6U	84HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6U	63HP	1	Hinged, Bottom	Anodized	Conductive
20838-274	6U	42HP	1	Hinged, Bottom	Anodized	Conductive


Table 2/2						
Katalognummer	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)	Hurtigforsendelse
20838-280	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	141.9mm	Nej
20838-271	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	213mm	Nej
20838-272	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	319.7mm	Nej
20838-273	No	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	426.4mm	Nej
20838-277	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	213mm	Nej
20838-278	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	319.7mm	Nej
20838-279	No	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	426.4mm	Nej

Katalognummer	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)	Hurtigforsendelse
20838-276	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	426.4mm	Nej
20838-275	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	319.7mm	Nej
20838-274	No	IEC 60297-3-101, IEEE 1101.1/10	No	261.8mm	213mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Front panel can be removed in opened position (> 135°).

DIAGRAMS

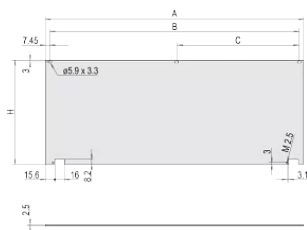

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, feilanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfeil.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE