


# Guide Rail Accessories for Heavy PCBs, Extra Strong

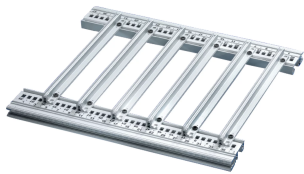

This reinforced guide rail for heavy PCBs of the type accessory, forms a reliable interface between the subrack mechanics and the sub-assemblies. The guide rails can additionally be bolted to the horizontal

## CERTIFICERINGER



## FUNKTIONER

For especially heavy PCBs, plug-in units or frame type plug-in units

Mounting, for bolting to type H (heavy) and type R (rugged) horizontal rails only

Aluminium profile

## SPECIFIKATIONER

|                        |                                                                                    |
|------------------------|------------------------------------------------------------------------------------|
| <b>Materiale:</b>      | Aluminium                                                                          |
| <b>Finish:</b>         | Anodized                                                                           |
| <b>Works With:</b>     | Subracks; Cases; Chassis                                                           |
| <b>Produktfamilie:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac |
| <b>Product Type:</b>   | Guide Rail                                                                         |
| <b>Type:</b>           | Heavy Duty                                                                         |

Table 1/1

| Katalognummer | Pakke mængde | Board Depth | Groove Width | Farve | Hurtigforsendelse |
|---------------|--------------|-------------|--------------|-------|-------------------|
|---------------|--------------|-------------|--------------|-------|-------------------|

|           |   |       |     |        |     |
|-----------|---|-------|-----|--------|-----|
| 34562-881 | 1 | 160mm | 2   | Silver | Nej |
| 34562-882 | 1 | 220mm | 2   | Silver | Nej |
| 34562-883 | 1 | 280mm | 2   | Silver | Nej |
| 34562-884 | 1 | 340mm | 2   | Silver | Nej |
| 34562-885 | 1 | 400mm | 2   | Silver | Nej |
| 34564-881 | 1 | 160mm | 2.5 | Silver | Nej |
| 34564-882 | 1 | 220mm | 2.5 | Silver | Nej |
| 34564-883 | 1 | 280mm | 2.5 | Silver | Nej |
| 34564-884 | 1 | 340mm | 2.5 | Silver | Nej |
| 34564-885 | 1 | 400mm | 2.5 | Silver | Nej |

## YDERLIGERE PRODUKTOPLYSNINGER

Delivery is exclusively in standard pack quantity.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**