


Guide Rail With Coding for CompactPCI/ VME64x, PC

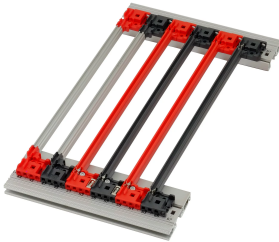

New generation of Wih Coding type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

CERTIFICERINGER



FUNKTIONER

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to a optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

Optional ESD clip for an conductive contact between PCB and horizontal rail available

Storage temperature: from -40 °C ... 130 °C

SPECIFIKATIONER

Works With:	Subracks; Cases; 19" Chassis; Systems
Type:	Coding
Produktfamilie:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type:	Guide Rail

Table 1/2

Katalognummer	Materiale	Farve	Pakke mængde	Board Depth	Groove Width	Complies With
64568-089	Fiber-Reinforced Plastic	Red	1	160mm	2	EN 45545-2
64568-090	Fiber-Reinforced Plastic	Grey	1	160mm	2	EN 45545-2
64568-109	Fiber-Reinforced Plastic, Aluminium	Red, Silver	1	160mm	2.5	EN 45545-2
64568-110	Fiber-Reinforced Plastic, Aluminium	Grey, Silver	1	160mm	2.5	EN 45545-2
24568-357	Fiber-Reinforced Plastic	Red	10	70mm	2	EN 45545-2
24568-360	Fiber-Reinforced Plastic	Grey	10	70mm	2	EN 45545-2
24568-358	Fiber-Reinforced Plastic	Grey	10	160mm	2	EN 45545-2
24568-356	Fiber-Reinforced Plastic	Red	10	160mm	2	EN 45545-2
24568-341	Fiber-Reinforced Plastic, Aluminium	Grey, Silver	10	280mm	2.5	EN 45545-2
24568-331	Fiber-Reinforced Plastic, Aluminium	Red, Silver	10	280mm	2.5	EN 45545-2
24568-332	Fiber-Reinforced Plastic, Aluminium	Red, Silver	10	340mm	2.5	EN 45545-2
24568-342	Fiber-Reinforced Plastic, Aluminium	Grey, Silver	10	340mm	2.5	EN 45545-2

Katalognummer	Materiale	Farve	Pakke mængde	Board Depth	Groove Width	Complies With
64568-085	Fiber-Reinforced Plastic	Red	1	70mm	2	EN 45545-2
64568-086	Fiber-Reinforced Plastic	Grey	1	70mm	2	EN 45545-2
64568-091	Fiber-Reinforced Plastic	Red	1	220mm	2	EN 45545-2
64568-092	Fiber-Reinforced Plastic	Grey	1	220mm	2	EN 45545-2
64568-111	Fiber-Reinforced Plastic, Aluminium	Red, Silver	1	220mm	2.5	EN 45545-2
64568-112	Fiber-Reinforced Plastic, Aluminium	Grey, Silver	1	220mm	2.5	EN 45545-2

Table 2/2

Katalognummer	Finish	Hurtigforsendelse
64568-089		Nej
64568-090		Nej
64568-109		Nej
64568-110		Nej
24568-357		Nej
24568-360		Nej
24568-358		Nej
24568-356		Nej

Katalognummer	Finish	Hurtigforsendelse
24568-341	Anodized	Nej
24568-331	Anodized	Nej
24568-332	Anodized	Nej
24568-342		Nej
64568-085		Nej
64568-086		Nej
64568-091		Nej
64568-092		Nej
64568-111		Nej
64568-112		Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE