


Guide Rail With Coding, preassembled ESD Clip for CompactPCI/ VME64x, PC

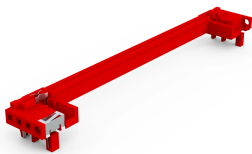

CERTIFICERINGER



FUNKTIONER

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

SPEKIFIKATIONER

Works With:	Subracks; Cases; 19" Chassis; Systems
Type:	Coding and Preassembled ESD Clips
Produktfamilie:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Materiale:	Fiber-Reinforced Plastic
Product Type:	Guide Rail

Table 1/2

Katalognummer	Farve	Pakke mængde	Board Depth	Groove Width	Complies With	Rail Type
24568-853	Red	10	70mm	2	EN 45545-2	Top
24568-855	Red	10	70mm	2	EN 45545-2	Bottom
24568-854	Grey	10	70mm	2	EN 45545-2	Top
24568-856	Grey	10	70mm	2	EN 45545-2	Bottom
24568-847	Red	10	160mm	2	EN 45545-2	Bottom
24568-850	Red	10	160mm	2	EN 45545-2	Top
24568-848	Grey	10	160mm	2	EN 45545-2	Bottom
24568-851	Grey	10	160mm	2	EN 45545-2	Top

Table 2/2

Katalognummer	Hurtigforsendelse
24568-853	Nej
24568-855	Nej
24568-854	Nej
24568-856	Nej
24568-847	Nej
24568-850	Nej
24568-848	Nej
24568-851	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE