


IP-PRO Aluminum Case, EMC

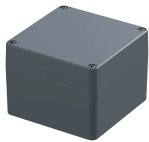

IP-Pro Alu EMC - The enclosure for reliable protection from water, dust and electromagnetic interferences for sensitive electronics in harsh environments. Proven and certified for applications with high shock and vibration requirements.

FUNKTIONER

Aluminum die-cast enclosure available in 15 different sizes, with outdoor powder coating in the color silver gray (RAL 7001)

Depending on size, protection class up to IP67 according to EN 60529

EMC-shielded

Shock and vibration resistant according to EN 61373 Cat. 2 and AREMA Class I

IK 09 protection from external mechanical impacts according to IEC 62262

Temperature range of the enclosure –40 to +90°C

SPECIFIKATIONER

Materiale:	Aluminium
Produktfamilie:	IP-PRO ALU EMC
Farvekode:	RAL 7001
Type:	Rugged
Product Type:	Small Form Factor Case

Table 1/2

Katalognummer	Højde	Bredde	Dybde	Beskyttelsesgrad	Pakke mængde	Farve
26880-001	90mm	122mm	122mm	IP67	1	Silver Grey
26880-002	90mm	220mm	122mm	IP67	1	Silver Grey

Katalognummer	Højde	Bredde	Dybde	Beskyttelsesgrad	Pakke mængde	Farve
26880-003	90mm	160mm	160mm	IP67	1	Silver Grey
26880-004	90mm	260mm	160mm	IP67	1	Silver Grey
26880-005	90mm	360mm	160mm	IP65	1	Silver Grey
26880-006	110mm	200mm	230mm	IP67	1	Silver Grey
26880-007	180mm	200mm	230mm	IP67	1	Silver Grey
26880-008	110mm	330mm	230mm	IP65	1	Silver Grey
26880-009	180mm	330mm	230mm	IP65	1	Silver Grey
26880-010	110mm	401mm	230mm	IP65	1	Silver Grey
26880-011	110mm	600mm	230mm	IP67	1	Silver Grey
26880-012	110mm	402mm	310mm	IP65	1	Silver Grey
26880-013	180mm	402mm	310mm	IP65	1	Silver Grey
26880-014	110mm	600mm	310mm	IP67	1	Silver Grey
26880-015	180mm	600mm	310mm	IP67	1	Silver Grey

Table 2/2

Katalognummer	Finish	Shape	Hurtigforsendelse
26880-001	Struktur Pulvermaling	Rectangular	Nej
26880-002	Struktur Pulvermaling	Rectangular	Nej
26880-003	Struktur Pulvermaling	Rectangular	Nej
26880-004	Struktur Pulvermaling	Rectangular	Nej

Katalognummer	Finish	Shape	Hurtigforsendelse
26880-005	Struktur Pulvermaling	Rectangular	Nej
26880-006	Struktur Pulvermaling	Rectangular	Nej
26880-007	Struktur Pulvermaling	Rectangular	Nej
26880-008	Struktur Pulvermaling	Rectangular	Nej
26880-009	Struktur Pulvermaling	Rectangular	Nej
26880-010	Struktur Pulvermaling	Rectangular	Nej
26880-011	Struktur Pulvermaling	Rectangular	Nej
26880-012	Struktur Pulvermaling	Rectangular	Nej
26880-013	Struktur Pulvermaling	Rectangular	Nej
26880-014	Struktur Pulvermaling	Rectangular	Nej
26880-015	Struktur Pulvermaling	Rectangular	Nej

YDERLIGERE PRODUKTOPLYSNINGER

For mechanical modifications, innovative PCB and cable fixing solutions, as well as cooling concepts, please contact us.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE