


Labrack C-Rail for 19" Stationary

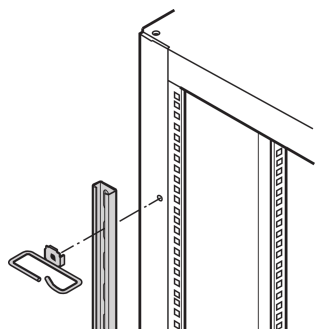

For assembly to the vertical uprights on the right and left hand side of the 19" plane; especially suited for cable eyes.

CERTIFICERINGER



FUNKTIONER

For assembly to the vertical uprights on the right and left hand side of the 19" plane; especially suited for cable eyes

SPECIFIKATIONER

Product Type: C-Rail
Materiale: Stål
Finish: Forzinket Stål

Table 1/1

Katalognummer	Rack Height	Pakke mængde	Length	Hurtigforsendelse
20118-461	24U	2	1050mm	Nej
22114-461	39U	2	1650mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please order assembly kit separately. Not suitable on mobile 19" lab racks.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE