


Mounting Plate for 19" Case and Subrack

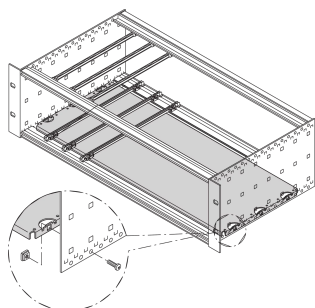

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICERINGER



FUNKTIONER

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

SPECIFIKATIONER

Materiale:	Aluminium
Product Type:	Mounting Plate
Works With:	Subracks

Table 1/2

Katalognummer	Rack Width	Pakke mængde	Dybde	Produktfamilie	Bredde	Certificeringer
34562-745	28HP	1	112.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS

Katalognummer	Rack Width	Pakke mængde	Dybde	Produktfamilie	Bredde	Certificeringer
34562-749	28HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-746	42HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-753	28HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-747	63HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-757	28HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-750	42HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	217.99mm	RoHS
34562-748	84HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-754	42HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-751	63HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	324.67mm	RoHS
34562-758	42HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-752	84HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	431.35mm	RoHS
34562-755	63HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-759	63HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS

Katalognummer	Rack Width	Pakke mængde	Dybde	Produktfamilie	Bredde	Certificeringer
34562-756	84HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-760	84HP	1	292.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-870	84HP	1	352.5mm	EuropacPRO	431.35mm	
34562-871	84HP	1	412.5mm	EuropacPRO	431.35mm	

Table 2/2

Katalognummer	Hurtigforsendelse
34562-745	Nej
34562-749	Nej
34562-746	Nej
34562-753	Nej
34562-747	Nej
34562-757	Nej
34562-750	Nej
34562-748	Nej
34562-754	Nej
34562-751	Nej
34562-758	Nej
34562-752	Nej

Katalognummer	Hurtigforsendelse
34562-755	Nej
34562-759	Nej
34562-756	Nej
34562-760	Nej
34562-870	Nej
34562-871	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE