


# MultipacPRO 19" Chassis Basic Kit

Such a kit enables a customer to configure the 3 different top / bottom covers.

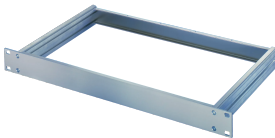

## CERTIFICERINGER



## FUNKTIONER

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Material: aluminium

Select further components (Accessories)

## SPECIFIKATIONER

|                        |                    |
|------------------------|--------------------|
| <b>Materiale:</b>      | Aluminium          |
| <b>Type:</b>           | Configurable       |
| <b>Produktfamilie:</b> | MultipacPRO        |
| <b>EMC Shielding:</b>  | No (Retrofittable) |
| <b>Product Type:</b>   | Subrack/Chassis    |

Table 1/2

| Katalognummer | Rack Height | Dybde | Usable Width | Mounting | Complies With   | Certificeringer |
|---------------|-------------|-------|--------------|----------|-----------------|-----------------|
| 20860-201     | 1U          | 220mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |

| Katalognummer | Rack Height | Dybde | Usable Width | Mounting | Complies With   | Certificeringer |
|---------------|-------------|-------|--------------|----------|-----------------|-----------------|
| 20860-202     | 1U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-203     | 1U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-204     | 1U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 |                 |
| 20860-205     | 1U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 |                 |
| 20860-210     | 2U          | 220mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-231     | 4U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-211     | 2U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-212     | 2U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-213     | 2U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 |                 |
| 20860-214     | 2U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 |                 |
| 20860-219     | 3U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-220     | 3U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-221     | 3U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-228     | 4U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-222     | 3U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-229     | 4U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-230     | 4U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |
| 20860-240     | 5U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS            |

Table 2/2

| Katalognummer | Hurtigforsendelse |
|---------------|-------------------|
| 20860-201     | Nej               |
| 20860-202     | Nej               |
| 20860-203     | Nej               |
| 20860-204     | Nej               |
| 20860-205     | Nej               |
| 20860-210     | Nej               |
| 20860-231     | Nej               |
| 20860-211     | Nej               |
| 20860-212     | Nej               |
| 20860-213     | Nej               |
| 20860-214     | Nej               |
| 20860-219     | Nej               |
| 20860-220     | Nej               |
| 20860-221     | Nej               |
| 20860-228     | Nej               |
| 20860-222     | Nej               |
| 20860-229     | Nej               |
| 20860-230     | Nej               |

| Katalognummer | Hurtigforsendelse |
|---------------|-------------------|
| 20860-240     | Nej               |

## YDERLIGERE PRODUKTOPLYSNINGER

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**