

Plug-In Unit Front Panel for Static Trapezoid Handle



The front panel enables the assembly of a plastic or Alu-profile static trapezoid handle. The front panel cannot be shielded with a textile gasket.

CERTIFICERINGER



FUNKTIONER

Front panel, unshielded

Front panel, Al, 2.5 mm, front anodized, conductive

SPECIFIKATIONER

Dybde (D):	2.5mm
Materiale:	Aluminium
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel for Handle (PIU)

Table 1/3

Katalognummer	Rack Height	Rack Width	Pakke mængde	Håndtagstype	Mounting	Front Finish
---------------	-------------	------------	--------------	--------------	----------	--------------

30847-602	3U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-603	3U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-604	3U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-605	3U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-625	6U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-606	3U	7HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-607	3U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-626	6U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-608	3U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-627	6U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-629	6U	7HP	1	Trapezoid, Static	Screw-on Front	Anodized
30847-609	3U	12HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

30847-628	6U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-630	6U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-631	6U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-632	6U	12HP	1	Trapezoid, Static	Screw-on Front	Anodized

Table 2/3

Katalognummer	Rear Finish	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)
30847-602	Conductive	No	IEC 60297-3-101	No	128.4mm	14.9mm
30847-603	Conductive	No	IEC 60297-3-101	No	128.4mm	20mm
30847-604	Conductive	No	IEC 60297-3-101	No	128.4mm	25mm
30847-605	Conductive	No	IEC 60297-3-101	No	128.4mm	30.1mm
30847-625	Conductive	No	IEC 60297-3-101	No	261.8mm	14.9mm
30847-606	Conductive	No	IEC 60297-3-101	No	128.4mm	35.2mm
30847-607	Conductive	No	IEC 60297-3-101	No	128.4mm	40.3mm
30847-626	Conductive	No	IEC 60297-3-101	No	261.8mm	20mm
30847-608	Conductive	No	IEC 60297-3-101	No	128.4mm	50.5mm
30847-627	Conductive	No	IEC 60297-3-101	No	261.8mm	25mm
30847-629	Conductive	No	IEC 60297-3-101	No	261.8mm	35.2mm


Katalognummer	Rear Finish	Treated Edges	Complies With	EMC Shielding	Højde (H)	Bredde (W)
30847-609	Conductive	No	IEC 60297-3-101	No	128.4mm	60.6mm
30847-628	Conductive	No	IEC 60297-3-101	No	261.8mm	30.1mm
30847-630	Conductive	No	IEC 60297-3-101	No	261.8mm	40.3mm
30847-631	Conductive	No	IEC 60297-3-101	No	261.8mm	50.5mm
30847-632	Conductive	No	IEC 60297-3-101	No	261.8mm	60.6mm

Table 3/3

Katalognummer	Hurtigforsendelse
30847-602	Nej
30847-603	Nej
30847-604	Nej
30847-605	Nej
30847-625	Nej
30847-606	Nej
30847-607	Nej
30847-626	Nej
30847-608	Nej
30847-627	Nej
30847-629	Nej
30847-609	Nej

Katalognummer	Hurtigforsendelse
30847-628	Nej
30847-630	Nej
30847-631	Nej
30847-632	Nej

DIAGRAMS

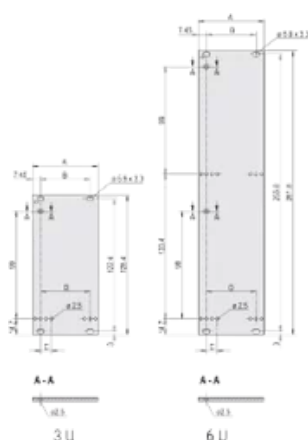

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl,

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE