

Plug-In Unit Kit With IEL Handle, Shielded, Black, 6 U



Plug-in unit, with IEL inserter/extractor black handle, 6 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

CERTIFICERINGER



FUNKTIONER

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

SPECIFIKATIONER

Materiale:	Aluminium
Finish:	Anodized; Passivated
Product Type:	Front Panel
Type:	Front Panel with Handle (PIU)

Table 1/3

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Mounting	EMC Gasket Type	Front Finish
---------------	------------	--------------	--------------	----------	-----------------	--------------


20848-592	4HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-594	6HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-596	8HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-597	10HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized
20848-598	12HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile	Anodized

Table 2/3						
Katalognummer	Rear Finish	Treated Edges	Complies With	EMC Shielding	Højde (H)	Rack Height
20848-592	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-594	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-596	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-597	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U
20848-598	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	261.8mm	6U

Table 3/3		
Katalognummer	Bredde (W)	Hurtigforsendelse

20848-592	20mm	Nej
20848-594	30.1mm	Nej
20848-596	40.3mm	Nej
20848-597	50.5mm	Nej
20848-598	60.6mm	Nej

DIAGRAMS

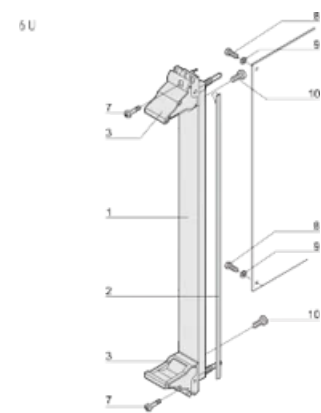

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, eller anden form for forkert brug af produktet kan resultere i skade på produktet og/eller installationen.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE