

Plug-In Unit Kit With Trapezoid Handle, Unshielded, Grey



Plug-in unit, with static handle and the flat front panel. The grey handle is assembled on the front panel.

CERTIFICERINGER



FUNKTIONER

Flat front panel

Handle without extraction function

SPECIFIKATIONER

Materiale:	Aluminium
Finish:	Anodized; Passivated
Product Type:	Front Panel
Type:	Front Panel with Handle (PIU)

Table 1/3

Katalognummer	Rack Height	Rack Width	Pakke mængde	Håndtagstype	Mounting	Front Finish
20818-017	3U	3HP	1	Trapezoid, Static	Screw-on Front	Anodized

Katalognummer	Rack Height	Rack Width	Pakke mængde	Håndtagstype	Mounting	Front Finish
20818-018	3U	4HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-019	3U	5HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-021	3U	7HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-022	3U	8HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-023	3U	10HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-026	6U	5HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-024	3U	12HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-027	6U	6HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-162	6U	7HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-029	6U	10HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-120	6U	12HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-020	3U	6HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-025	6U	4HP	1	Trapezoid, Static	Screw-on Front	Anodized
20818-028	6U	8HP	1	Trapezoid, Static	Screw-on Front	Anodized

Table 2/3

Katalognummer	Rear Finish	Treated Edges	Flammability Rating	Complies With	EMC Shielding	Højde (H)
20818-017	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm

Katalognummer	Rear Finish	Treated Edges	Flammability Rating	Complies With	EMC Shielding	Højde (H)
20818-018	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-019	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-021	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-022	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-023	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-026	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm
20818-024	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-027	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm
20818-162	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm
20818-029	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm
20818-120	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm


Katalognummer	Rear Finish	Treated Edges	Flammability Rating	Complies With	EMC Shielding	Højde (H)
20818-020	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	128.4mm
20818-025	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm
20818-028	Passivated	No	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	No	261.8mm

Table 3/3

Katalognummer	Bredde (W)	Hurtigforsendelse
20818-017	14.9mm	Nej
20818-018	20mm	Nej
20818-019	25mm	Nej
20818-021	35.2mm	Nej
20818-022	40.3mm	Nej
20818-023	50.5mm	Nej
20818-026	25mm	Nej
20818-024	60.6mm	Nej
20818-027	30.1mm	Nej
20818-162	35.2mm	Nej
20818-029	50.5mm	Nej
20818-120	60.6mm	Nej

Katalognummer	Bredde (W)	Hurtigforsendelse
20818-020	30.1mm	Nej
20818-025	20mm	Nej
20818-028	40.3mm	Nej

DIAGRAMS

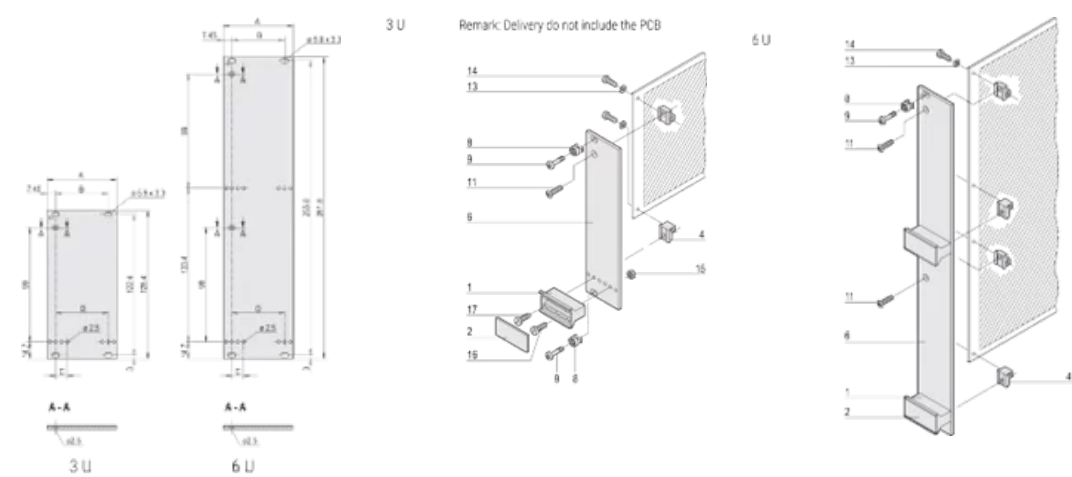

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE