

Plug-In Units Front Panel for Handle Form 1



Flat front panel. Enables the assembly of form 1 trapezoid form extraction handle. The front panel can be shielded with a textile gasket.

CERTIFICERINGER



FUNKTIONER

Front panel, unshielded

Front panel, Al, 2.5 mm, front anodized, rear conductive

SPECIFIKATIONER

Materiale:	Aluminium
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel with Handle (PIU)

Table 1/3

Katalognummer	Rack Height	Rack Width	Pakke mængde	Håndtagstype	Mounting	Front Finish
30847-661	3U	6HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-659	3U	4HP	1	Trapezoid, Type 1	Screw-on Front	Anodized

Katalognummer	Rack Height	Rack Width	Pakke mængde	Håndtagstype	Mounting	Front Finish
30847-660	3U	5HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-662	3U	7HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-663	3U	8HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-666	6U	4HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-664	3U	10HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-667	6U	5HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-665	3U	12HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-668	6U	6HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-669	6U	7HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-670	6U	8HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-671	6U	10HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30847-672	6U	12HP	1	Trapezoid, Type 1	Screw-on Front	Anodized

Table 2/3

Katalognummer	Rear Finish	Treated Edges	Complies With	Dybde (D)	EMC Shielding	Højde (H)
30847-661	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm
30847-659	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm
30847-660	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm

Katalognummer	Rear Finish	Treated Edges	Complies With	Dybde (D)	EMC Shielding	Højde (H)
30847-662	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm
30847-663	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm
30847-666	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm
30847-664	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm
30847-667	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm
30847-665	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	128.4mm
30847-668	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm
30847-669	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm
30847-670	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm
30847-671	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm
30847-672	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	No	261.8mm


Table 3/3

Katalognummer	Bredde (W)	Hurtigforsendelse
30847-661	30.1mm	Nej
30847-659	20mm	Nej
30847-660	25mm	Nej

Katalognummer	Bredde (W)	Hurtigforsendelse
30847-662	35.2mm	Nej
30847-663	40.3mm	Nej
30847-666	20mm	Nej
30847-664	50.5mm	Nej
30847-667	25mm	Nej
30847-665	60.6mm	Nej
30847-668	30.1mm	Nej
30847-669	35.2mm	Nej
30847-670	40.3mm	Nej
30847-671	50.5mm	Nej
30847-672	60.6mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

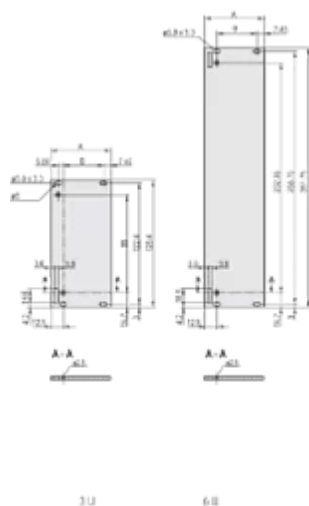

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE