


# Socket Strip, IEC C19

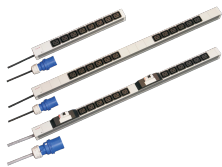

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with IEC C19 outlets.

## CERTIFICERINGER



## FUNKTIONER

Socket strips with C19 IEC sockets

Socket strips can be rotated through all four directions (in 90° increments) during installation

Connecting cable 2 m, with connector in accordance with IEC 60309

Mounting height 1 U

## SPECIFIKATIONER

**Materiale:** Aluminium; Polyamide

**Farve:** Grey

**Product Type:** Socket Strip

Table 1/2

| Katalognummer | Stiktype | Socket Quantity | Switched Outlets | Spænding AC | Pakke mængde | Dybde |
|---------------|----------|-----------------|------------------|-------------|--------------|-------|
| 60110-280     | IEC C19  | 8               | No               | 230V        | 1            | 44mm  |
| 60110-282     | IEC C19  | 12              | No               | 230V        | 1            | 44mm  |

| Katalognummer | Stiktype | SocketQuantity | Switched Outlets | Spænding AC | Pakke mængde | Dybde |
|---------------|----------|----------------|------------------|-------------|--------------|-------|
| 60110-281     | IEC C19  | 12             | No               | 230V        | 1            | 44mm  |

Table 2/2

| Katalognummer | Finish   | Højde | Length  | Hurtigforsendelse |
|---------------|----------|-------|---------|-------------------|
| 60110-280     | Anodized | 44mm  | 438.5mm | Nej               |
| 60110-282     | Anodized | 44mm  | 947.5mm | Nej               |
| 60110-281     | Anodized | 44mm  | 947.5mm | Nej               |

## YDERLIGERE PRODUKTOPLYSNINGER

Please order bracket for vertical mounting separately.

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**