


Static Handle Plastic in Trapezoid Form, Black

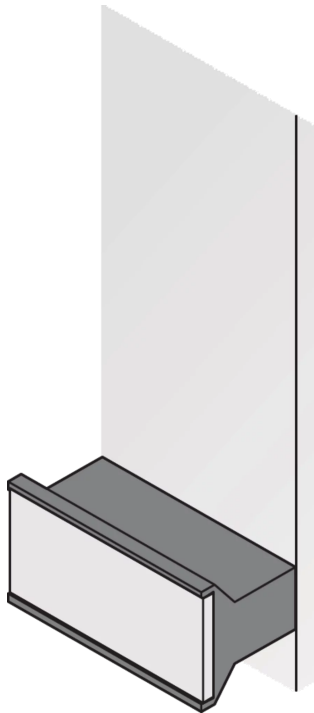

The static plastic handle, trapezoid form in black color can be mounted to a front panel for extraction of the PCB.

CERTIFICERINGER



FUNKTIONER

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFIKATIONER

Works With:	Front Panels
Product Type:	Handle
Materiale:	Polycarbonate
Type:	Static

Table 1/2

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Flammability Rating	Farve	Complies With
20808-080	5HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-081	6HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-082	7HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-083	8HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-084	9HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-085	10HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-086	12HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-087	14HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-088	21HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-089	28HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-090	40HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Flammability Rating	Farve	Complies With
20808-091	42HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-396	3HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-397	4HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Table 2/2

Katalognummer	Bredde (W)	Hurtigforsendelse
20808-080	24mm	Nej
20808-081	29mm	Nej
20808-082	34.1mm	Nej
20808-083	39.2mm	Nej
20808-084	44.3mm	Nej
20808-085	49.4mm	Nej
20808-086	59.6mm	Nej
20808-087	69.7mm	Nej
20808-088	105.2mm	Nej
20808-089	140.8mm	Nej
20808-090	201.8mm	Nej
20808-091	212mm	Nej


Katalognummer	Bredde (W)	Hurtigforsendelse
20809-396	13.8mm	Nej
20809-397	18.9mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

DIAGRAMS

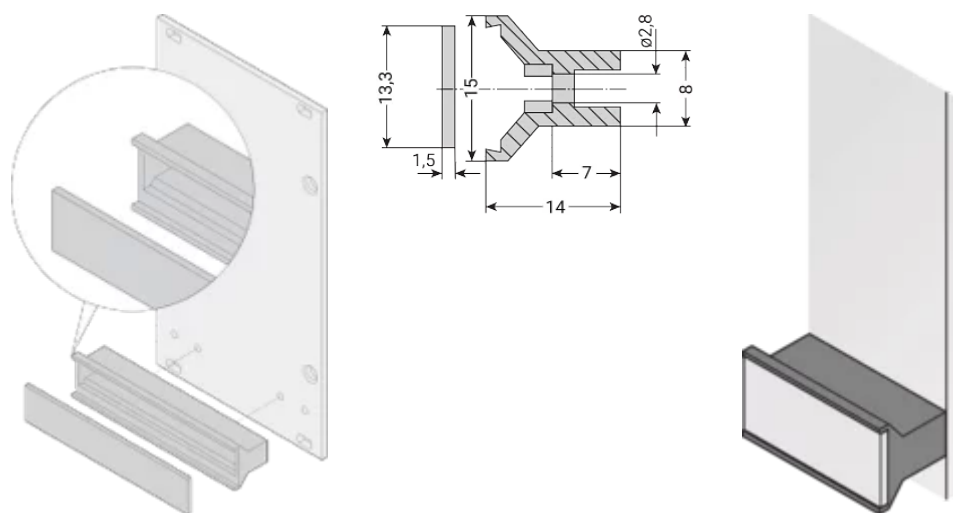

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE