


Static Handle Plastic in Trapezoid Form, Grey

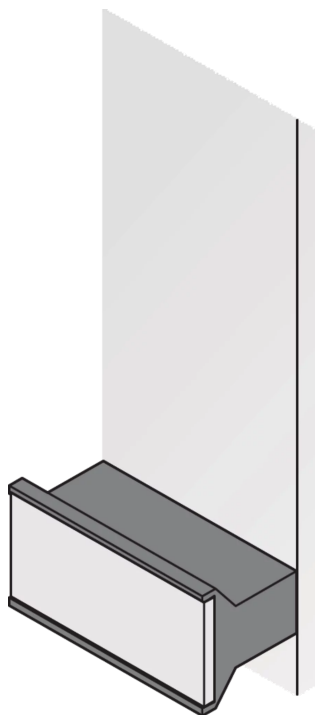

The static plastic handle, trapezoid form in grey color can be mounted to a front panel for extraction of the PCB.

CERTIFICERINGER



FUNKTIONER

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFIKATIONER

Works With:	Front Panels
Product Type:	Handle
Materiale:	Polyphenylene Ether
Type:	Static

Table 1/2

Katalognummer	Rack Width	Pakke mængde	Håndtagstype	Flammability Rating	Farve	Farvekode
20808-062	8HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-004	10HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-067	28HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-009	40HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-068	42HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-012	61HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-003	5HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-060	6HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-061	7HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-063	9HP	1	Trapezoid, Static	UL® 94V-0	Grey	
20808-064	12HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-065	14HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20808-066	21HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-294	3HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035
20809-295	4HP	1	Trapezoid, Static	UL® 94V-0	Light Grey	RAL 7035

Table 2/2

Katalognummer	Complies With	Dybde (D)	Højde (H)	Bredde (W)	Hurtigforsendelse
20808-062	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	39.2mm	Nej


Katalognummer	Complies With	Dybde (D)	Højde (H)	Bredde (W)	Hurtigforsendelse
20808-004	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	49.4mm	Nej
20808-067	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	140.8mm	Nej
20808-009	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			201.8mm	Nej
20808-068	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	212mm	Nej
20808-012	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			308.5mm	Nej
20808-003	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	24mm	Nej
20808-060	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	29mm	Nej
20808-061	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	34.1mm	Nej
20808-063	EN 45545-2, R22-R24, HL3, IEC 60297-3-101			44.3mm	Nej
20808-064	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	59.6mm	Nej
20808-065	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	69.7mm	Nej
20808-066	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	14mm	15.4mm	105.2mm	Nej
20809-294	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	13.8mm	Nej
20809-295	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	16.3mm	15.4mm	18.9mm	Nej

YDERLIGERE PRODUKTOPLYSNINGER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

DIAGRAMS

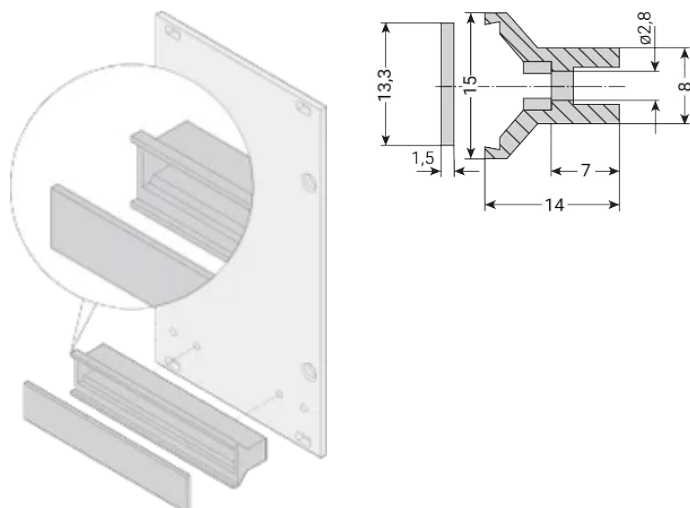

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE